


Digital Tubular Inside Micrometer (Rod)

Item number: 337-302

Images

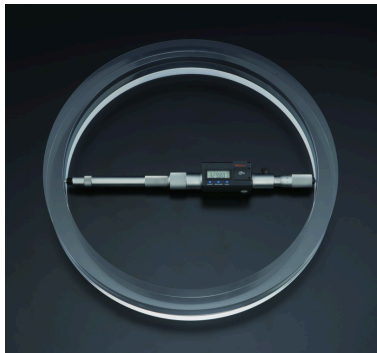

Dust- and Water-Protected

www.tuv.com
ID 0000021605



Description

This is an extension rod type inside micrometer that offers you the following benefits:


- Interchangeable extensions with cylindrical gage rods are spring-mounted in protective sleeves so you can extend the measuring range.
- Carbide measuring faces.
- Digimatic type, with data output.
- It has excellent resistance against water and dust (IP65 protection level) enabling you to use it in machining situations that include splashing coolant fluid.

Features

Inch-Metric:	Metric
Digital/Analog:	Digital
Range:	200 - 1,500 mm
Measuring span:	25 mm
Digital step:	0,001 mm
Spindle feed error:	3 µm

Limit of error:	±(3+number of rods+max. measurement length/50) µm
Power supply:	1 battery SR-44
Scale:	Thimble and sleeve satin chrome finish, ø18 mm
Display:	LCD, character height 7.5 mm
Measuring spindle:	Spindle pitch 0.5 mm
Measuring face:	Carbide
Extension:	ø12,5 mm
Extension rods:	7 (25, 50, 100, 200, 300 (3 pcs.))
DATA/HOLD:	Yes
ABS / INC (INC ZERO):	Yes
Auto Power OFF after 20 min. non use:	Yes
Low voltage alarm:	Yes
Function lock:	Yes
2 x PRESET:	Yes
Delivered:	Including box, spanner, 1 SR44 battery, 7 extension rods, micrometer head (main unit) 137-101
Data output:	Yes
Mass:	1410 g

Dimensions

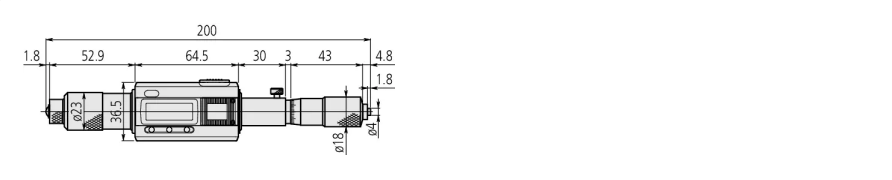

Accessories

Optional accessories:

Promotion!

Mitutoyo

MiCAT
the standard in world metrology software
measurLink

USB-ITPAK Vers. 3.0
USB Dongle + Manual (Software available Online)
Art No. 06AGR543
Promo price: 268.00 €*
~~Suggested retail price: 340.00 €*~~

USB-ITPAK

Spare parts

Consumable spares:



Battery SR44 1,5 V

Art No. 938882

Suggested retail price: 7.00 €*
