
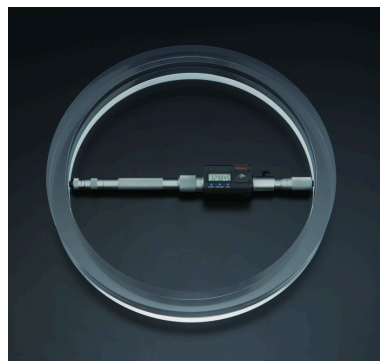


## Digital Tubular Inside Micrometer (Pipe)

Item number: 339-302

### Images

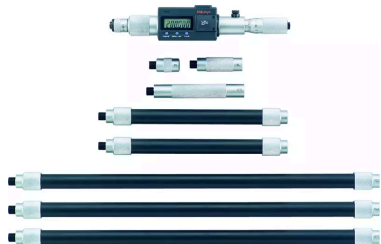

Dust- and Water-Protected

www.tuv.com  
ID 0000021605



### Description


A Mitutoyo digital inside micrometer covering a range of measurement by using a set of interchangeable extension tubes that can be used singly or in combination. The micrometer head is satin-chrome finished.

### Features

<b>Model:</b>	IMJ-2000MJ
<b>Inch-Metric:</b>	Metric
<b>Digital/Analog:</b>	Digital
<b>Range:</b>	200 - 2,000 mm
<b>Measuring span:</b>	25 mm
<b>Digital step:</b>	0,001 mm
<b>Spindle feed error:</b>	3 $\mu$ m


<b>Limit of error:</b>	±(3+number of rods+max. measurement length/50) μm
<b>Power supply:</b>	1 battery SR-44
<b>Scale:</b>	Thimble and sleeve satin chrome finish, ø18 mm
<b>Display:</b>	LCD, character height 7.5 mm
<b>Measuring spindle:</b>	Spindle pitch 0,5 mm
<b>Measuring face:</b>	Carbide
<b>Extension:</b>	ø17 mm
<b>Extension rods:</b>	8 (25, 50, 100, 200 (2 pcs.), 400 mm (3 pcs.))
<b>DATA/HOLD:</b>	Yes
<b>ABS / INC (INC ZERO):</b>	Yes
<b>Auto Power OFF after 20 min. non use:</b>	Yes
<b>Low voltage alarm:</b>	Yes
<b>Function lock:</b>	Yes
<b>2 x PRESET:</b>	Yes
<b>Delivered:</b>	Including box, spanner, 1 SR44 battery, 8 extension rods, micrometer head (main unit) 139-101
<b>Data output:</b>	Yes
<b>Mass:</b>	1800 g

**Dimensions**

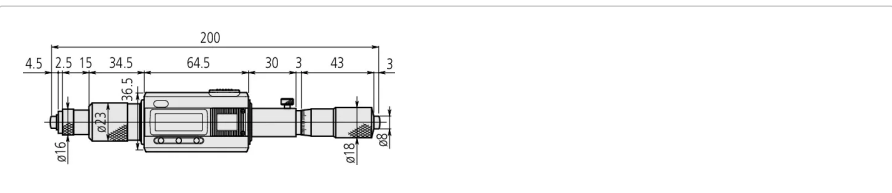

**Accessories**

Optional accessories:



**Digimatic Cable with Data Button IP Type**

1 m, Micrometer Type  
 Art No. 05CZA662  
 Suggested retail price: 105.00 €\*



## Digimatic Cable with Data Button IP Type

2 m, Micrometer Type

Art No. 05CZA663

Suggested retail price: 107.00 €\*

Promotion!

Mitutoyo

MiCAT

the standard in world  
metrology software  
MeasurLink

## USB-ITPAK Vers. 3.0

USB Dongle + Manual (Software available Online)

Art No. 06AGR543

Promo price: **268.00 €\***

Suggested retail price: ~~340.00 €\*~~



USB-ITPAK

## Spare parts

Consumable spares:



## Battery SR44 1,5 V

Art No. 938882

Suggested retail price: 7.00 €\*