


Digital Tubular Inside Micrometer (Pipe)

Item number: 339-303

Images

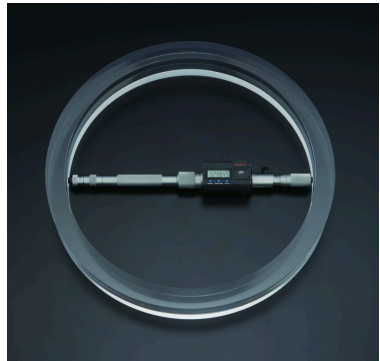

Dust- and Water-Protected

www.tuv.com
ID 0000021605



Description

A Mitutoyo digital inside micrometer covering a range of measurement by using a set of interchangeable extension tubes that can be used singly or in combination. The micrometer head is satin-chrome finished.

Features

Inch-Metric:	Inch/Metric
Digital/Analog:	Digital
Range:	8 - 40 "
Measuring span:	1"
Digital step:	0.0001"/0.001 mm
Limit of error:	$\pm(0,00015+0,00005 \times \text{number of rods} + 0,00005(\text{max. measurement length}/2))"$
Power supply:	1 battery SR-44
Scale:	Thimble and sleeve satin chrome finish, $\varnothing 18$ mm
Display:	LCD, character height 7.5 mm

USB Input Tool Direct (Digimatic to USB)



2m Cable, with Data Button IP Micrometer Type

Art No. 06ADV380B

Suggested retail price: 119.00 €*
~~119.00 €*~~

Promotion!



Connection Cable B for U-WAVE

with Data Button for IP Micrometer Type

Art No. 02AZD790B

Promo price: **76.00 €*
~~110.00 €*~~**

Suggested retail price: 110.00 €*
~~110.00 €*~~



Connection Cable B for U-WAVE

for Foot Switch, with Data Button for IP Micrometer Type

Art No. 02AZE140B

Suggested retail price: 157.00 €*
~~157.00 €*~~

Optional accessories:

Promotion!

Mitutoyo

MiCAT

the standard in world
metrology software
MeasurLink®

USB-ITPAK Vers. 3.0

USB Dongle + Manual (Software available Online)

Art No. 06AGR543

Promo price: **268.00 €*
~~340.00 €*~~**

Suggested retail price: 340.00 €*
~~340.00 €*~~

USB-ITPAK

Spare parts

Consumable spares:



Battery SR44 1,5 V

Art No. 938882

Suggested retail price: 7.00 €*
