

Digital Micrometer Interchangeable Anvil

Item number: 340-351-30

Images



Description

This Digimatic Micrometer offers you an extra wide measuring range, and has the following benefits:

- Easy, interchangeable anvils allow a wide range of measurements.
- Ratchet stop for constant force.

Features

Digital/Analog:	Digital
Inch-Metric:	Inch/Metric
Range:	0 - 6 "
Digital step:	0.00005"/0.001 mm
Limit of error:	±0,0003"
Delivered:	Including box, spanner, setting standard, 6 anvils, 1 SR44 battery
Spindle feed error:	0.00015 inch
Flatness:	0,000024"
Parallelism:	0.00012"
Display:	LCD, character height 7.5 mm
Measuring face:	Carbide tipped, micro-lap finish spindle and hardened steel anvil

Measuring spindle:	With spindle lock, $\varnothing 6,35$ mm (≤ 300 mm) \varnothing 8 mm (> 300 mm) , spindle pitch 0,5 mm
Scale:	Thimble and sleeve satin chrome finish, $\varnothing 18$ mm
Data output:	Yes
Measuring force:	5 - 10 N
Power supply:	Battery SR-44
Battery life:	Approx. 2.4 years, Approx. 1.8 years (> 300 mm)
Setting standard:	5 (1, 2, 3, 4, 5")
Interchangeable anvils:	6
ABS / INC (INC ZERO):	Yes
Auto Power OFF after 20 min. non use:	Yes
Low voltage alarm:	Yes
Function lock:	Yes
HOLD:	Yes
2 x PRESET:	Yes
Mass:	0.96 kg

Accessories

Optional accessories:

Promotion!



Connection Unit for IP Caliper, Micrometer

with Data Button for U-WAVE fit, U-WAVE fit Bluetooth

Art No. 02AZF310

Promo price: **76.00 €***

Suggested retail price: ~~110.00 €*~~

Promotion!



USB Input Tool Direct (Digimatic to USB)

2m Cable, Digimatic/Digimatic 2, with Data Button IP Micrometer Type

Art No. 06AFM380B

Promo price: **111.00 €***

Suggested retail price: ~~141.00 €*~~



Digimatic Cable with Data Button IP Type

1 m, Micrometer Type
Art No. 05CZA662
Suggested retail price: 105.00 €*



Digimatic Cable with Data Button IP Type

2 m, Micrometer Type
Art No. 05CZA663
Suggested retail price: 107.00 €*

Promotion!



U-WAVE fit, IP67 Type

Wireless Transmitter for
Micrometer/Indicator
Art No. 264-622
**Promo price: 129.00 €*
Suggested retail price: 185.00 €*

---**

Promotion!



U-WAVE fit, Buzzer Type

Wireless Transmitter for
Micrometer/Indicator
Art No. 264-623
**Promo price: 129.00 €*
Suggested retail price: 185.00 €*

---**

Promotion!



U-WAVE fit Bluetooth, IP67 Type

Wireless Transmitter for
Micrometer/Indicator
Art No. 264-626
**Promo price: 129.00 €*
Suggested retail price: 185.00 €*

---**

Promotion!



U-WAVE fit Bluetooth, Buzzer Type

Wireless Transmitter for
Micrometer/Indicator
Art No. 264-627

Promo price: **129.00 €***
Suggested retail price: ~~185.00 €*~~

Promotion!

Mitutoyo

MiCAT
the standard in world
metrology software
MeasurLink

USB-ITPAK Vers. 3.0

USB Dongle + Manual (Software available
Online)


Art No. 06AGR543

Promo price: **268.00 €***
Suggested retail price: ~~340.00 €*~~



Standard accessories:

Micrometer Setting Standard

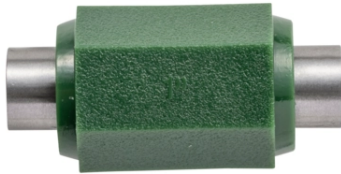

Length: 1"
Art No. 167-141
Suggested retail price: **33.00 €***

Micrometer Setting Standard



Length: 2"
Art No. 167-142
Suggested retail price: **36.00 €***

Micrometer Setting Standard



Length: 3"
Art No. 167-143
Suggested retail price: **37.00 €***

Micrometer Setting Standard

Length: 4"

Art No. 167-144

Suggested retail price: 38.00 €*



Micrometer Setting Standard

Length: 5"

Art No. 167-145

Suggested retail price: 41.00 €*



Spare parts

Consumable spares:



Battery SR44 1,5 V

Art No. 938882

Suggested retail price: 7.00 €*
