


Digital Micrometer Interchangeable Anvil

Item number: 340-522

Images

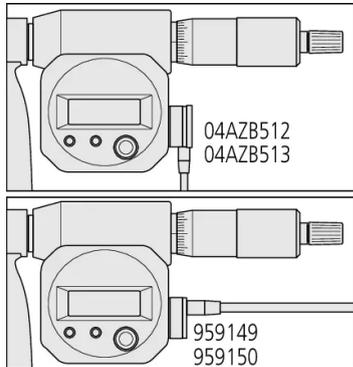

Description

This Digimatic Micrometer offers you an extra wide measuring range, and has the following benefits:

- Easy, interchangeable anvils allow a wide range of measurements.
- Ratchet stop for constant force.

Features

Digital/Analog:	Digital
Delivered:	Including box, spanner, setting standard, 4 anvils, 2 SR44 batteries
Inch-Metric:	Metric
Range:	500 - 600 mm
Digital step:	0,001 mm
Limit of error:	$\pm 12 \mu\text{m}$
Spindle feed error:	$3 \mu\text{m}$
Flatness:	$1 \mu\text{m}$
Parallelism:	$8 \mu\text{m}$
Display:	LCD, character height 7.5 mm
Measuring face:	Carbide tipped, micro-lap finish spindle and hardened steel anvil
Measuring spindle:	With spindle lock, $\varnothing 6,35 \text{ mm}$ ($\leq 300 \text{ mm}$) $\varnothing 8 \text{ mm}$ ($> 300 \text{ mm}$), spindle pitch 0,5 mm
Scale:	Thimble and sleeve satin chrome finish, $\varnothing 21 \text{ mm}$
Measuring force:	10 - 15 N
Power supply:	Battery SR-44

Battery life: Approx. 2.4 years for models ≤300 mm
1.8 years for >300 mm

Setting standard: 4 (500, 525, 550, 575 mm)

Interchangeable anvils: 4

ABS / INC (INC ZERO): Yes

Auto Power OFF after 20 min. non use: Yes

Low voltage alarm: Yes


Function lock: Yes

HOLD: Yes

2 x PRESET: Yes

Mass: 5.5 kg

Dimensions

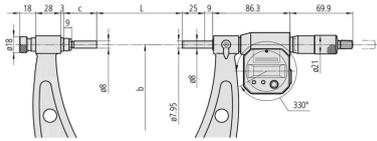

Accessories

Optional accessories:

Promotion!



Connection Cable C for U-WAVE

Straight, with Data Button
Art No. 02AZD790C

Promo price: **63.90 €***

Suggested retail price: ~~105.00 €*~~

Promotion!



USB Input Tool Direct (Digimatic to USB)

2m Cable, Digimatic/Digimatic 2, Straight, with Data Button

Art No. 06AFM380C

Promo price: **98.90 €***

Suggested retail price: ~~124.00 €*~~



Digimatic Cable, Straight, Data Button,

1m
Art No. 959149
Suggested retail price: 48.00 €*



Digimatic Cable, Straight, Data Button

2m
Art No. 959150
Suggested retail price: 57.00 €*



Digimatic Cable with Data Button

1m, Flat L-Shape Left Type
Art No. 04AZB512
Suggested retail price: 95.00 €*



Digimatic Cable, Straight, Data Button

2m, Flat L-Shape Left Type
Art No. 04AZB513
Suggested retail price: 106.00 €*

Promotion!



U-WAVE-T, IP67 Type

Wireless Transmitter
Art No. 02AZD730G
Promo price: **129.00 €***
Suggested retail price: ~~187.00 €*~~

Promotion!



U-WAVE-T, Buzzer Type

Wireless Transmitter

Art No. 02AZD880G

Promo price: **129.00 €***

Suggested retail price: ~~187.00 €*~~

Promotion!

Mitutoyo

MiCAT

the standard in world
metrology software
MeasurLink®

USB-ITPAK Vers. 3.0

USB Dongle + Manual (Software available
Online)

Art No. 06AGR543

Promo price: **259.00 €***

Suggested retail price: ~~340.00 €*~~



Standard accessories:

Micrometer Setting Standard

Length: 500mm

Art No. 167-120

Suggested retail price: **159.00 €***



Micrometer Setting Standard

Length: 525mm

Art No. 167-121

Suggested retail price: **171.00 €***



Micrometer Setting Standard

Length: 550mm

Art No. 167-122

Suggested retail price: **176.00 €***



Micrometer Setting Standard

Length: 575mm

Art No. 167-123

Suggested retail price: 188.00 €*



Spare parts

Consumable spares:



Battery SR44 1,5 V

Art No. 938882

Suggested retail price: 10.00 €*
