


Digital Micrometer Interchangeable Anvil

Item number: 340-722

Images

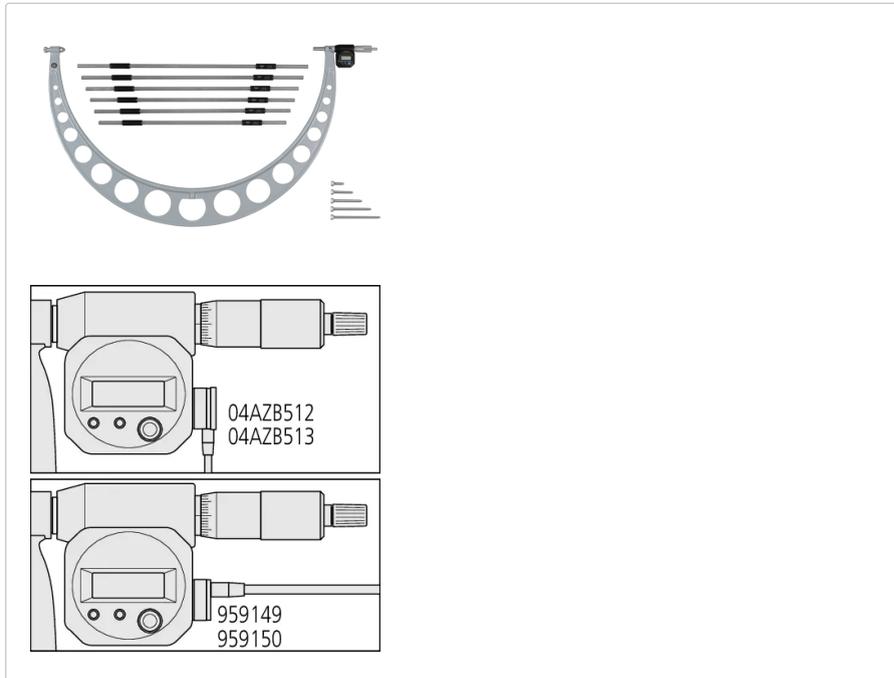

Description


A Mitutoyo digital micrometer provided with easily interchangeable anvils to enable a wide measuring range from one instrument. A ratchet stop guarantees repeatable measurement. Digimatic data output.

Features

Digital/Analog:	Digital
Delivered:	Including box, spanner, setting standard, 6 anvils, 2 SR44 batteries
Inch-Metric:	Inch/Metric
Range:	24 - 30 "
Digital step:	0.0001"/0.001 mm
Limit of error:	±0,0006"
Spindle feed error:	0.00015 inch
Flatness:	0,00004"
Parallelism:	0.0004"
Display:	LCD, character height 7.5 mm
Measuring face:	Carbide tipped, micro-lap finish spindle and hardened steel anvil
Measuring spindle:	With spindle lock, $\varnothing 6,35$ mm (≤ 300 mm) $\varnothing 8$ mm (> 300 mm) , spindle pitch 0,5 mm
Scale:	Thimble and sleeve satin chrome finish, $\varnothing 21$ mm
Measuring force:	10 - 15 N
Power supply:	Battery SR-44

Battery life:	Approx. 2.4 years for models ≤300 mm 1.8 years for >300 mm
Setting standard:	6 (24, 25, 26, 27, 28, 29")
Interchangeable anvils:	6
ABS / INC (INC ZERO):	Yes
Auto Power OFF after 20 min. non use:	Yes
Low voltage alarm:	Yes
Function lock:	Yes
HOLD:	Yes
2 x PRESET:	Yes
Mass:	7.7 kg

Dimensions

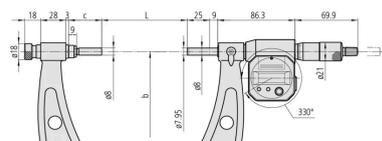

L: 600 mm

Accessories

Optional accessories:

Promotion!



Connection Cable C for U-WAVE

Straight, with Data Button
Art No. 02AZD790C
Promo price: **63.90 €***
Suggested retail price: ~~105.00 €*~~

Promotion!



USB Input Tool Direct (Digimatic to USB)

2m Cable, Digimatic/Digimatic 2, Straight, with Data Button
Art No. 06AFM380C
Promo price: **98.90 €***
Suggested retail price: ~~124.00 €*~~



Digimatic Cable, Straight, Data Button,

1m
Art No. 959149
Suggested retail price: 48.00 €*



Digimatic Cable, Straight, Data Button

2m
Art No. 959150
Suggested retail price: 57.00 €*



Digimatic Cable with Data Button

1m, Flat L-Shape Left Type
Art No. 04AZB512
Suggested retail price: 95.00 €*



Digimatic Cable, Straight, Data Button

2m, Flat L-Shape Left Type
Art No. 04AZB513
Suggested retail price: 106.00 €*

Promotion!



U-WAVE-T, IP67 Type

Wireless Transmitter
Art No. 02AZD730G
Promo price: **129.00 €***
Suggested retail price: ~~187.00 €*~~

Promotion!



U-WAVE-T, Buzzer Type

Wireless Transmitter

Art No. 02AZD880G

Promo price: **129.00 €***

Suggested retail price: ~~187.00 €*~~

Promotion!

Mitutoyo

MiCAT

the standard in world
metrology software
MeasurLink*

USB-ITPAK Vers. 3.0

USB Dongle + Manual (Software available
Online)

Art No. 06AGR543

Promo price: **259.00 €***

Suggested retail price: ~~340.00 €*~~



Standard accessories:

Micrometer Setting Standard

Length: 24"

Art No. 167-164

Suggested retail price: **201.00 €***



Micrometer Setting Standard

Length: 25"

Art No. 167-165

Suggested retail price: **222.00 €***



Micrometer Setting Standard

Length: 26"

Art No. 167-166

Suggested retail price: **234.00 €***



Micrometer Setting Standard

Length: 27"

Art No. 167-167

Suggested retail price: 248.00 €*


Micrometer Setting Standard

Length: 28"

Art No. 167-168

Suggested retail price: 261.00 €*


Micrometer Setting Standard

Length: 29"

Art No. 167-169

Suggested retail price: 272.00 €*


Spare parts

Consumable spares:



Battery SR44 1,5 V

Art No. 938882

Suggested retail price: 10.00 €*
