

Digital Point Micrometer IP65

Item number: 342-262-30

Images



Dust- and
Water-
Protected

www.tuv.com
ID 0000040191



Description

This Digimatic Point Micrometer features a pointed anvil and spindle, and offers the following benefits:

- Its pointed anvil and spindle has a choice of included angle, ending in small-radius contact points.
- You can use it to measure grooves, steps and similar.

Features

Model:	CPM30-50MX
Digital/Analog:	Digital
Inch-Metric:	Metric
Range:	25 - 50 mm
Digital step:	0,001 mm
Max. Permissible Error J MPE:	±2 µm
Delivered:	Including box, spanner, setting standard, 1 SR44 battery
Display:	LCD, character height 7.5 mm
Measuring face:	Carbide pointed spindle and anvil, measuring point radius 0.3 mm
Tip:	30°

Measuring spindle: With spindle lock, $\varnothing 6,35$ mm, spindle pitch 0,5 mm

Scale: Thimble and sleeve satin chrome finish, $\varnothing 18$ mm

Data output: Yes

Measuring force: 3 - 8 N

Power supply: 1 battery SR-44

Battery life: Approx. 2.4 years

ORIGIN: Yes

ABS / INC (INC ZERO): Yes

Auto Power OFF after 20 min. non use: Yes


Low voltage alarm: Yes

Function lock: Yes

HOLD: Yes

Mass: 470 g

Dimensions

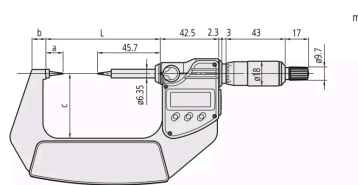


L: 83.2 mm

a: 12.5 mm

b: 10.1 mm

c: 47 mm

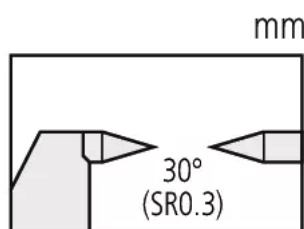

L: 83.2 mm

a: 12.5 mm

b: 10.1 mm

c: 47 mm

Accessories

Optional accessories:



Micrometer Stand, 45° Angle Type

for Micrometer 0-50mm/0-2"

Art No. 156-105-10

Suggested retail price: 58.00 €*

Promotion!



Micrometer Stand, Adjustable Angle Type

for Micrometer 0-100mm/0-4"

Art No. 156-101-10

Promo price: **56.00 €***

Suggested retail price: ~~70.00 €*~~

Promotion!



Connection Unit for IP Caliper, Micrometer

with Data Button for U-WAVE fit, U-WAVE fit Bluetooth

Art No. 02AZF310

Promo price: **76.00 €***

Suggested retail price: ~~110.00 €*~~

Promotion!



USB Input Tool Direct (Digimatic to USB)

2m Cable, Digimatic/Digimatic 2, with Data Button IP Micrometer Type

Art No. 06AFM380B

Promo price: **111.00 €***

Suggested retail price: ~~141.00 €*~~



Digimatic Cable with Data Button IP Type

1 m, Micrometer Type

Art No. 05CZA662

Suggested retail price: **105.00 €***



Digimatic Cable with Data Button IP Type

2 m, Micrometer Type

Art No. 05CZA663

Suggested retail price: **107.00 €***

Promotion!



U-WAVE fit, IP67 Type

Wireless Transmitter for
Micrometer/Indicator
Art No. 264-622

Promo price: **129.00 €***
Suggested retail price: ~~185.00 €*~~

Promotion!



U-WAVE fit, Buzzer Type

Wireless Transmitter for
Micrometer/Indicator
Art No. 264-623

Promo price: **129.00 €***
Suggested retail price: ~~185.00 €*~~

Promotion!



U-WAVE fit Bluetooth, IP67 Type

Wireless Transmitter for
Micrometer/Indicator
Art No. 264-626

Promo price: **129.00 €***
Suggested retail price: ~~185.00 €*~~

Promotion!



U-WAVE fit Bluetooth, Buzzer Type

Wireless Transmitter for
Micrometer/Indicator
Art No. 264-627

Promo price: **129.00 €***
Suggested retail price: ~~185.00 €*~~

Promotion!

Mitutoyo


MiCAT
the standard in world
metrology software
MesurLink

USB-ITPAK Vers. 3.0

USB Dongle + Manual (Software available
Online)

Art No. 06AGR543

Promo price: **268.00 €***
Suggested retail price: ~~340.00 €*~~

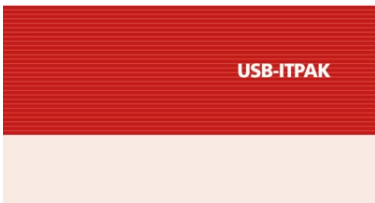

USB-ITPAK

Standard accessories:

Micrometer Setting Standard



Length: 25mm
Art No. 167-101
Suggested retail price: 33.00 €*

Spare parts

Consumable spares:



Battery SR44 1,5 V

Art No. 938882
Suggested retail price: 7.00 €*
