

Digital Crimp Height Micrometer IP65

Item number: 342-271-30

Images



Description

This Crimp Height Micrometer that features a flat anvil and pointed spindle offers you the following benefits:


- It allows you to measure the crimped height of electrical contacts.
- Excellent resistance against water and dust (IP65 protection level).

Features

Model:	CHM-20MX
Digital/Analog:	Digital
Inch-Metric:	Metric
Range:	0 - 20 mm
Digital step:	0,001 mm
Max. Permissible Error J MPE:	±3 µm
Delivered:	Including box, spanner, 1 SR44 battery
Display:	LCD, character height 7.5 mm
Measuring face:	Hardened steel, micro-lap finish
Measuring spindle:	With spindle lock, ø 6.35 mm, spindle pitch 0.5 mm (342-271-30, 112-401) without spindle lock ø 6.35 mm, spindle pitch (342-451-20) 10 mm
Scale:	Thimble and sleeve satin chrome finish, ø18 mm
Data output:	Yes

Measuring force:	3 - 8 N
Power supply:	1 battery SR-44
Battery life:	Approx. 2.4 years (342-271-30), 5 years (342-451-20)
ORIGIN:	Yes
ABS / INC (INC ZERO):	Yes
Auto Power OFF after 20 min. non use:	Yes
Low voltage alarm:	Yes
Function lock:	Yes
HOLD:	Yes
Mass:	270 g

Dimensions

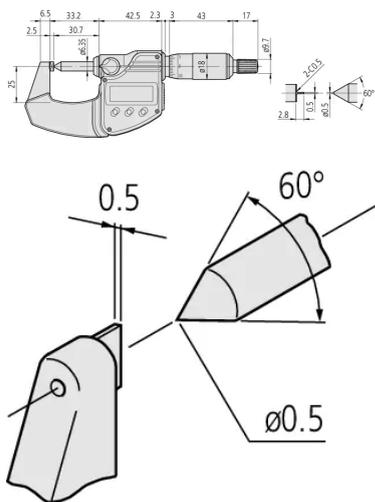

Accessories

Proposed additional product:



Connection Cable B for U-WAVE

with Data Button for IP Micrometer Type
Art No. 02AZD790B

Promo price: **76.00 €***

~~Suggested retail price: 110.00 €*~~

Promotion!



Connection Cable E for U-WAVE

Round 6-Pin Type
Art No. 02AZD790E

Promo price: **68.00 €***
Suggested retail price: ~~98.00 €*~~

Promotion!



USB Input Tool Direct (Digimatic to USB)

2m Cable, Digimatic/Digimatic 2, with Data Button IP Micrometer Type
Art No. 06AFM380B

Promo price: **111.00 €***
Suggested retail price: ~~141.00 €*~~

Digimatic Cable with Data Button IP Type



1 m, Micrometer Type
Art No. 05CZA662
Suggested retail price: 105.00 €*

Digimatic Cable with Data Button IP Type



2 m, Micrometer Type
Art No. 05CZA663
Suggested retail price: 107.00 €*

Promotion!



USB Input Tool Direct (Digimatic to USB)

2m Cable, Digimatic/Digimatic 2, Round 6-Pin Type
Art No. 06AFM380E

Promo price: **98.00 €***
Suggested retail price: ~~124.00 €*~~



Digimatic Cable, Round 6-Pin Type

1 m
Art No. 937387
Suggested retail price: 60.00 €*



Digimatic Cable, Round 6-Pin Type

2 m
Art No. 965013
Suggested retail price: 72.00 €*

Optional accessories:



Micrometer Stand, 45° Angle Type

for Micrometer 0-50mm/0-2"
Art No. 156-105-10
Suggested retail price: 58.00 €*

Promotion!



Micrometer Stand, Adjustable Angle Type

for Micrometer 0-100mm/0-4"
Art No. 156-101-10
Promo price: 56.00 €*
Suggested retail price: 70.00 €*

Promotion!



Connection Unit for IP Caliper, Micrometer

with Data Button for U-WAVE fit, U-WAVE fit
Bluetooth
Art No. 02AZF310
Promo price: 76.00 €*
Suggested retail price: 110.00 €*

Promotion!



USB Input Tool Direct (Digimatic to USB)

2m Cable, Digimatic/Digimatic 2, with Data
Button IP Micrometer Type
Art No. 06AFM380B

Promo price: **111.00 €***
Suggested retail price: ~~141.00 €*~~



Digimatic Cable with Data Button IP Type

1 m, Micrometer Type
Art No. 05CZA662
Suggested retail price: 105.00 €*



Digimatic Cable with Data Button IP Type

2 m, Micrometer Type
Art No. 05CZA663
Suggested retail price: 107.00 €*

Promotion!



U-WAVE fit, IP67 Type

Wireless Transmitter for
Micrometer/Indicator
Art No. 264-622

Promo price: **129.00 €***
Suggested retail price: ~~185.00 €*~~

Promotion!



U-WAVE fit, Buzzer Type

Wireless Transmitter for
Micrometer/Indicator
Art No. 264-623

Promo price: **129.00 €***
Suggested retail price: ~~185.00 €*~~

Promotion!



U-WAVE fit Bluetooth, IP67 Type

Wireless Transmitter for
Micrometer/Indicator
Art No. 264-626

Promo price: **129.00 €***
Suggested retail price: ~~185.00 €*~~

Promotion!



U-WAVE fit Bluetooth, Buzzer Type

Wireless Transmitter for
Micrometer/Indicator
Art No. 264-627

Promo price: **129.00 €***
Suggested retail price: ~~185.00 €*~~

Promotion!

Mitutoyo

MICAT

the standard in world
metrology software
measurLink

USB-ITPAK Vers. 3.0

USB Dongle + Manual (Software available
Online)

Art No. 06AGR543

Promo price: **268.00 €***
Suggested retail price: ~~340.00 €*~~



Spare parts

Consumable spares:



Battery SR44 1,5 V

Art No. 938882
Suggested retail price: 7.00 €*

Spare part:



Battery SR44 1,5 V

Art No. 938882

Suggested retail price: 7.00 €*
