


Digital Crimp Height Micrometer IP65

Item number: 342-371-30

Images

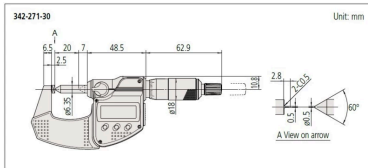

Description

This Crimp Height Micrometer that features a flat anvil and pointed spindle offers you the following benefits:

- It allows you to measure the crimped height of electrical contacts.
- Excellent resistance against water and dust (IP65 protection level).

Features

Digital/Analog:	Digital
Inch-Metric:	Inch/Metric
Range:	0 - 0.8 "
Graduation:	0.00005 in / 0.001 mm
Digital step:	0,0005"/0,001 mm
Max. Permissible Error J MPE:	±0.00015"
Delivered:	Including box, spanner, 1 SR44 battery
Display:	LCD, character height 7.5 mm
Measuring face:	Hardened steel, micro-lap finish
Measuring spindle:	With spindle lock, ø 6.35 mm, spindle pitch 0.5 mm (342-271-30, 112-401) without spindle lock ø 6.35 mm, spindle pitch (342-451-20) 10 mm
Scale:	Thimble and sleeve satin chrome finish, ø18 mm
Data output:	Yes
Measuring force:	3 - 8 N
Power supply:	1 battery SR-44
Battery life:	Approx. 2.4 years (342-271-30), 5 years (342-451-20)
ORIGIN:	Yes

ABS / INC (INC ZERO):	Yes
Auto Power OFF after 20 min. non use:	Yes
Low voltage alarm:	Yes
Function lock:	Yes
HOLD:	Yes
Mass:	275 g

Accessories


Proposed additional product:

Promotion!



Connection Cable B for U-WAVE
with Data Button for IP Micrometer Type
Art No. 02AZD790B
Promo price: 76.00 €*
~~Suggested retail price: 110.00 €*~~

Promotion!



Connection Cable E for U-WAVE
Round 6-Pin Type
Art No. 02AZD790E
Promo price: 68.00 €*
~~Suggested retail price: 98.00 €*~~

Promotion!



USB Input Tool Direct (Digimatic to USB)
2m Cable, Digimatic/Digimatic 2, with Data Button IP Micrometer Type
Art No. 06AFM380B
Promo price: 111.00 €*
~~Suggested retail price: 141.00 €*~~



Digimatic Cable with Data Button IP Type

1 m, Micrometer Type
Art No. 05CZA662
Suggested retail price: 105.00 €*



Digimatic Cable with Data Button IP Type

2 m, Micrometer Type
Art No. 05CZA663
Suggested retail price: 107.00 €*

Promotion!



USB Input Tool Direct (Digimatic to USB)

2m Cable, Digimatic/Digimatic 2, Round 6-Pin Type
Art No. 06AFM380E
Promo price: **98.00 €***
Suggested retail price: ~~124.00 €*~~



Digimatic Cable, Round 6-Pin Type

1 m
Art No. 937387
Suggested retail price: 60.00 €*



Digimatic Cable, Round 6-Pin Type

2 m
Art No. 965013
Suggested retail price: 72.00 €*

Optional accessories:



Micrometer Stand, 45° Angle Type

for Micrometer 0-50mm/0-2"
Art No. 156-105-10
Suggested retail price: 58.00 €*
*incl. VAT

Promotion!



Micrometer Stand, Adjustable Angle Type

for Micrometer 0-100mm/0-4"
Art No. 156-101-10
Promo price: **56.00 €*
Suggested retail price: 70.00 €*
*incl. VAT**

Promotion!



Connection Unit for IP Caliper, Micrometer

with Data Button for U-WAVE fit, U-WAVE fit Bluetooth
Art No. 02AZF310
Promo price: **76.00 €*
Suggested retail price: 110.00 €*
*incl. VAT**

Promotion!



USB Input Tool Direct (Digimatic to USB)

2m Cable, Digimatic/Digimatic 2, with Data Button IP Micrometer Type
Art No. 06AFM380B
Promo price: **111.00 €*
Suggested retail price: 141.00 €*
*incl. VAT**



Digimatic Cable with Data Button IP Type

1 m, Micrometer Type
Art No. 05CZA662
Suggested retail price: 105.00 €*
*incl. VAT



Digimatic Cable with Data Button IP Type

2 m, Micrometer Type
Art No. 05CZA663
Suggested retail price: 107.00 €*
Suggested retail price: 107.00 €*
Suggested retail price: 107.00 €*

Promotion!



U-WAVE fit, IP67 Type

Wireless Transmitter for
Micrometer/Indicator
Art No. 264-622
Promo price: **129.00 €***
Suggested retail price: ~~185.00 €*~~

Promotion!



U-WAVE fit, Buzzer Type

Wireless Transmitter for
Micrometer/Indicator
Art No. 264-623
Promo price: **129.00 €***
Suggested retail price: ~~185.00 €*~~

Promotion!



U-WAVE fit Bluetooth, IP67 Type

Wireless Transmitter for
Micrometer/Indicator
Art No. 264-626
Promo price: **129.00 €***
Suggested retail price: ~~185.00 €*~~

Promotion!



U-WAVE fit Bluetooth, Buzzer Type

Wireless Transmitter for
Micrometer/Indicator
Art No. 264-627
Promo price: **129.00 €***
Suggested retail price: ~~185.00 €*~~

Promotion!

Mitutoyo

MiCAT

the standard in world
metrology software
MeasurLink®

USB-ITPAK Vers. 3.0

USB Dongle + Manual (Software available
Online)

Art No. 06AGR543

Promo price: **268.00 €***

Suggested retail price: ~~340.00 €*~~

USB-ITPAK

Spare parts

Consumable spares:



Battery SR44 1,5 V

Art No. 938882

Suggested retail price: 7.00 €*

Spare part:



Battery SR44 1,5 V

Art No. 938882

Suggested retail price: 7.00 €*