

Digital Caliper Jaw Micrometer

Item number: 343-351-30

Images




Description

"DIGIMATIC" Outside Micrometer 1" - 2"

Features

Digital/Analog:	Digital
Inch-Metric:	Inch/Metric
Range:	1 - 2 "
Digital step:	0.00005"/0.001 mm
Max. Permissible Error J MPE:	±0.0003"
Delivered:	Including box, spanner, setting standard, 1 SR44 battery
Flatness:	0.000012"
Parallelism:	0.00012"
Display:	LCD, character height 7.5 mm
Measuring face:	Carbide-tipped, micro-lap finish
Measuring spindle:	With spindle lock, ø6,35 mm, spindle pitch 0,5 mm
Scale:	Thimble and sleeve satin chrome finish, ø18 mm
Data output:	Yes
Measuring force:	1 - 6 N
Power supply:	1 battery SR-44
Battery life:	Approx. 2.4 years
ORIGIN:	Yes
ABS / INC (INC ZERO):	Yes
Auto Power OFF after 20 min. non use:	Yes
Low voltage alarm:	Yes
Function lock:	Yes
HOLD:	Yes
Mass:	340 g

Dimensions

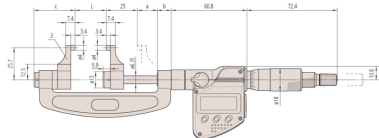

L: 25 mm

a: 16 mm

b: 10.6 mm

c: 32.9 mm

Accessories

Optional accessories:



Micrometer Stand, 45° Angle Type

for Micrometer 0-50mm/0-2"

Art No. 156-105-10

Suggested retail price: **58.00 €***

Promotion!



Micrometer Stand, Adjustable Angle Type

for Micrometer 0-100mm/0-4"

Art No. 156-101-10

Promo price: **56.00 €***

Suggested retail price: **70.00 €***

Promotion!



Connection Unit for IP Caliper, Micrometer

with Data Button for U-WAVE fit, U-WAVE fit Bluetooth

Art No. 02AZF310

Promo price: **76.00 €***

Suggested retail price: **110.00 €***

Promotion!



USB Input Tool Direct (Digimatic to USB)

2m Cable, Digimatic/Digimatic 2, with Data Button IP Micrometer Type

Art No. 06AFM380B

Promo price: **111.00 €***

Suggested retail price: **141.00 €***



Digimatic Cable with Data Button IP Type

1 m, Micrometer Type
Art No. 05CZA662
Suggested retail price: 105.00 €*
~~105.00 €~~



Digimatic Cable with Data Button IP Type

2 m, Micrometer Type
Art No. 05CZA663
Suggested retail price: 107.00 €*
~~107.00 €~~

Promotion!



U-WAVE fit, IP67 Type

Wireless Transmitter for
Micrometer/Indicator
Art No. 264-622
Promo price: 129.00 €*
Suggested retail price: 185.00 €*
~~185.00 €~~

Promotion!



U-WAVE fit, Buzzer Type

Wireless Transmitter for
Micrometer/Indicator
Art No. 264-623
Promo price: 129.00 €*
Suggested retail price: 185.00 €*
~~185.00 €~~

Promotion!



U-WAVE fit Bluetooth, IP67 Type

Wireless Transmitter for
Micrometer/Indicator
Art No. 264-626
Promo price: 129.00 €*
Suggested retail price: 185.00 €*
~~185.00 €~~

Promotion!



U-WAVE fit Bluetooth, Buzzer Type

Wireless Transmitter for
Micrometer/Indicator
Art No. 264-627


Promo price: **129.00 €***
~~Suggested retail price: 185.00 €*~~

Promotion!

Mitutoyo

MiCAT

the standard in world
metrology software
MeasurLink®

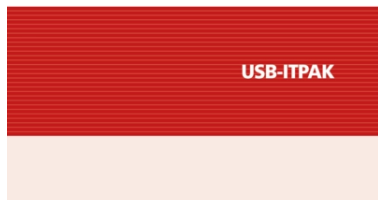

USB-ITPAK Vers. 3.0

USB Dongle + Manual (Software available
Online)

Art No. 06AGR543

Promo price: **268.00 €***
~~Suggested retail price: 340.00 €*~~

Standard accessories:



Micrometer Setting Standard

Length: 1"
Art No. 167-141
Suggested retail price: **33.00 €***

Spare parts

Consumable spares:



Battery SR44 1,5 V

Art No. 938882
Suggested retail price: **7.00 €***

