

Digital Micrometer Head

Item number: 350-253-30

Images



Description

This Micrometer Head has a 25 mm range and a 10 mm stem, and offers the following benefits:

- You can integrate it into machinery and measuring instruments.
- Measurement values are clearly displayed in 0.001 mm increments.
- Stem diameter: 10 mm.


Features

Model:	MHN3-25MX
Digital/Analog:	Digital
Inch-Metric:	Metric
Range:	0 - 25 mm
Digital step:	0,001 mm
Max. Permissible Error J MPE:	±2 μm
Spindle end:	Spherical (SR4)
Spindle pitch:	0,5 mm
Stem Ø:	10 mm
Stem:	Plain
Delivered:	Including spanner, SR44 battery
Display:	LCD, character Height 7.5 mm
Measuring face:	Carbide tipped
Measuring spindle:	With spindle lock, ø 6,35 mm
Scale:	Thimble and sleeve satin chrome finish
Data output:	Yes
Power supply:	1 battery SR-44
Battery life:	Approx. 2,4 years
ABS / INC (INC ZERO):	Yes
Auto Power OFF after 20 min. non use:	Yes
Low voltage alarm:	Yes
Function lock:	Yes
HOLD:	Yes
2 x PRESET:	Yes

Mass:

230 g

Dimensions

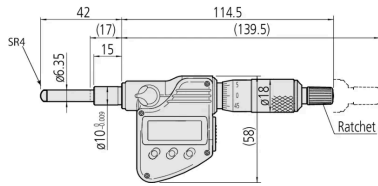

Accessories

Optional accessories:

Promotion!

Mitutoyo

MiCAT

the standard in world
metrology software
MeasurLink®

USB-ITPAK Vers. 3.0

USB Dongle + Manual (Software available
Online)

Art No. 06AGR543

Promo price: **268.00 €***

Suggested retail price: ~~340.00 €*~~

USB-ITPAK

Digimatic Cable with Data Button IP Type

1 m, Micrometer Type

Art No. 05CZA662

Suggested retail price: **105.00 €***



Digimatic Cable with Data Button IP Type

2 m, Micrometer Type

Art No. 05CZA663

Suggested retail price: **107.00 €***



Promotion!

USB Input Tool Direct (Digimatic to USB)

2m Cable, Digimatic/Digimatic 2, with Data
Button IP Micrometer Type

Art No. 06AFM380B

Promo price: **111.00 €***

Suggested retail price: ~~141.00 €*~~



Promotion!



U-WAVE fit, IP67 Type

Wireless Transmitter for
Micrometer/Indicator
Art No. 264-622

Promo price: **129.00 €***
Suggested retail price: ~~185.00 €*~~

Promotion!



U-WAVE fit, Buzzer Type

Wireless Transmitter for
Micrometer/Indicator
Art No. 264-623

Promo price: **129.00 €***
Suggested retail price: ~~185.00 €*~~

Promotion!



U-WAVE fit Bluetooth, Buzzer Type

Wireless Transmitter for
Micrometer/Indicator
Art No. 264-627

Promo price: **129.00 €***
Suggested retail price: ~~185.00 €*~~

Promotion!



U-WAVE fit Bluetooth, IP67 Type

Wireless Transmitter for
Micrometer/Indicator
Art No. 264-626

Promo price: **129.00 €***
Suggested retail price: ~~185.00 €*~~

Promotion!



Connection Unit for IP Caliper, Micrometer

with Data Button for U-WAVE fit, U-WAVE fit
Bluetooth
Art No. 02AZF310

Promo price: **76.00 €***
Suggested retail price: ~~110.00 €*~~



Fixture for Micrometer Head, Plain Stem

for 10mm Stem
Art No. 303583
Suggested retail price: 50.00 €*



Fixture for Micrometer Head, Plain Stem

for 10mm Stem
Art No. 303579
Suggested retail price: 50.00 €*



Fixture for Micrometer Head, Plain Stem

for 10mm Stem
Art No. 303581
Suggested retail price: 50.00 €*



Fixture for Micrometer Head, Plain Stem

for 10mm Stem
Art No. 303585
Suggested retail price: 50.00 €*

Spare parts

Consumable spares:



Battery SR44 1,5 V

Art No. 938882

Suggested retail price: 7.00 €*
