


# Digital Micrometer Head

Item number: 350-254-30

## Images

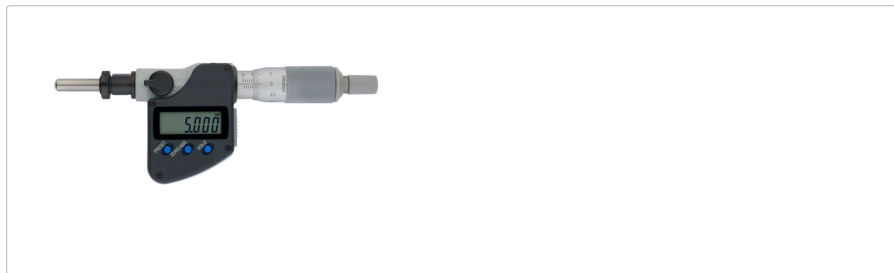

## Description

This Micrometer Head has a 25 mm range and a 10 mm stem, and offers the following benefits:

- You can integrate it into machinery and measuring instruments.
- Measurement values are clearly displayed in 0.001mm increments.
- Stem diameter: 10 mm.

## Features


<b>Model:</b>	MHN4-25MX
<b>Digital/Analog:</b>	Digital
<b>Inch-Metric:</b>	Metric
<b>Range:</b>	0 - 25 mm
<b>Digital step:</b>	0,001 mm
<b>Max. Permissible Error J MPE:</b>	±2 μm
<b>Spindle end:</b>	Spherical (SR4)
<b>Spindle pitch:</b>	0,5 mm
<b>Stem Ø:</b>	10 mm
<b>Stem:</b>	w/ clamp nut
<b>Fixture thickness for clamp nut:</b>	11.5 mm
<b>Delivered:</b>	Including spanner, SR44 battery
<b>Display:</b>	LCD, character Height 7.5 mm
<b>Measuring face:</b>	Carbide tipped
<b>Measuring spindle:</b>	With spindle lock, ø 6,35 mm
<b>Scale:</b>	Thimble and sleeve satin chrome finish
<b>Data output:</b>	Yes
<b>Power supply:</b>	1 battery SR-44
<b>Battery life:</b>	Approx. 2,4 years
<b>ABS / INC (INC ZERO):</b>	Yes
<b>Auto Power OFF after 20 min. non use:</b>	Yes
<b>Low voltage alarm:</b>	Yes
<b>Function lock:</b>	Yes

**HOLD:** Yes

**2 x PRESET:** Yes

**Mass:** 230 g

## Dimensions

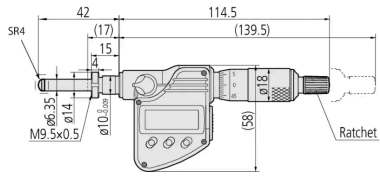

## Accessories

### Optional accessories:

Promotion!

Mitutoyo

MiCAT

the standard in world  
metrology software  
measurLink

### USB-ITPAK Vers. 3.0

USB Dongle + Manual (Software available Online)

Art No. 06AGR543

Promo price: **268.00 €\***

Suggested retail price: ~~340.00 €\*~~

USB-ITPAK

### Digimatic Cable with Data Button IP Type



1 m, Micrometer Type

Art No. 05CZA662

Suggested retail price: 105.00 €\*

### Digimatic Cable with Data Button IP Type



2 m, Micrometer Type

Art No. 05CZA663

Suggested retail price: 107.00 €\*

Promotion!



### USB Input Tool Direct (Digimatic to USB)

2m Cable, Digimatic/Digimatic 2, with Data  
Button IP Micrometer Type  
Art No. 06AFM380B

Promo price: **111.00 €\***

Suggested retail price: ~~141.00 €\*~~

Promotion!



### U-WAVE fit, IP67 Type

Wireless Transmitter for  
Micrometer/Indicator  
Art No. 264-622

Promo price: **129.00 €\***

Suggested retail price: ~~185.00 €\*~~

Promotion!



### U-WAVE fit, Buzzer Type

Wireless Transmitter for  
Micrometer/Indicator  
Art No. 264-623

Promo price: **129.00 €\***

Suggested retail price: ~~185.00 €\*~~

Promotion!



### U-WAVE fit Bluetooth, Buzzer Type

Wireless Transmitter for  
Micrometer/Indicator  
Art No. 264-627

Promo price: **129.00 €\***

Suggested retail price: ~~185.00 €\*~~

Promotion!



### U-WAVE fit Bluetooth, IP67 Type

Wireless Transmitter for  
Micrometer/Indicator  
Art No. 264-626

Promo price: **129.00 €\***

Suggested retail price: ~~185.00 €\*~~

Promotion!



### Connection Unit for IP Caliper, Micrometer

with Data Button for U-WAVE fit, U-WAVE fit Bluetooth

Art No. 02AZF310

Promo price: **76.00 €\***

Suggested retail price: ~~110.00 €\*~~



### Fixture for Micrometer Head, Clamp Nut

for 10mm Stem

Art No. 303578

Suggested retail price: 50.00 €\*



### Fixture for Micrometer Head, Clamp Nut

for 10mm Stem

Art No. 303582

Suggested retail price: 50.00 €\*




### Fixture for Micrometer Head, Clamp Nut

for 10mm Stem

Art No. 303580

Suggested retail price: 50.00 €\*

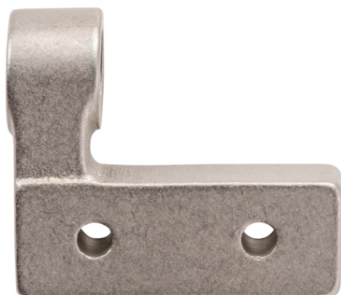

### Fixture for Micrometer Head, Clamp Nut

for 10mm Stem

Art No. 303584

Suggested retail price: 50.00 €\*

Consumable spares:

---



**Battery SR44 1,5 V**

Art No. 938882

Suggested retail price: 7.00 €\*  

---