

Digital Micrometer Head, Non Rot., IP65

Item number: 350-261-30

Images



Description

This Micrometer Head has a 25 mm range and a 12 mm stem, and offers the following benefits:


- You can integrate it into machinery and measuring instruments.
- Its excellent water and dust resistance (IP65 protection level) lets you use it in machining situations that include splashing coolant fluid (except types with threaded stem).

Features

Model:	MHN1-25MXN (IP65)
Digital/Analog:	Digital
Inch-Metric:	Metric
Range:	0 - 25 mm
Digital step:	0,001 mm
Max. Permissible Error J MPE:	±2 µm
Spindle end:	Flat
Spindle pitch:	0,5 mm
Stem Ø:	12 mm
Stem:	Plain
Delivered:	Including spanner, SR44 battery, stem bush D=12/18 mm
Remarks:	IP65, w/ non-rotating measuring face w/o ratched stop
Display:	LCD, character Height 7.5 mm
Measuring face:	Carbide tipped
Measuring spindle:	With spindle lock, ø 6,35 mm
Scale:	Thimble and sleeve satin chrome finish
Data output:	Yes

Power supply:	1 battery SR-44
Battery life:	Approx. 2,4 years
ABS / INC (INC ZERO):	Yes
Auto Power OFF after 20 min. non use:	Yes
Low voltage alarm:	Yes
Function lock:	Yes
HOLD:	Yes
2 x PRESET:	Yes
Mass:	235 g

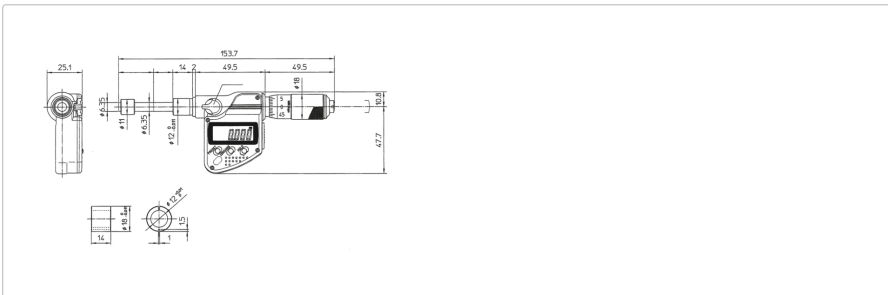


Dimensions



Accessories

Optional accessories:

Promotion!


USB-ITPAK Vers. 3.0

USB Dongle + Manual (Software available Online)

Art No. 06AGR543

Promo price: **268.00 €***

Suggested retail price: ~~340.00 €*~~

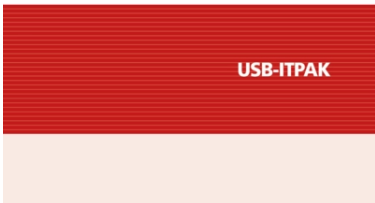


Digimatic Cable with Data Button IP Type

1 m, Micrometer Type
 Art No. 05CZA662
 Suggested retail price: 105.00 €*



Digimatic Cable with Data Button IP Type

2 m, Micrometer Type
Art No. 05CZA663
Suggested retail price: 107.00 €*
~~107.00 €*~~

Promotion!



USB Input Tool Direct (Digimatic to USB)

2m Cable, Digimatic/Digimatic 2, with Data Button IP Micrometer Type
Art No. 06AFM380B
Promo price: **111.00 €*
Suggested retail price: 141.00 €***

Promotion!



U-WAVE fit, IP67 Type

Wireless Transmitter for Micrometer/Indicator
Art No. 264-622
Promo price: **129.00 €*
Suggested retail price: 185.00 €***

Promotion!



U-WAVE fit, Buzzer Type

Wireless Transmitter for Micrometer/Indicator
Art No. 264-623
Promo price: **129.00 €*
Suggested retail price: 185.00 €***

Promotion!



U-WAVE fit Bluetooth, IP67 Type

Wireless Transmitter for Micrometer/Indicator
Art No. 264-626
Promo price: **129.00 €*
Suggested retail price: 185.00 €***

Promotion!



U-WAVE fit Bluetooth, Buzzer Type

Wireless Transmitter for
Micrometer/Indicator
Art No. 264-627

Promo price: **129.00 €***
~~Suggested retail price: 185.00 €*~~

Promotion!



Connection Unit for IP Caliper, Micrometer

with Data Button for U-WAVE fit, U-WAVE fit
Bluetooth

Art No. 02AZF310
Promo price: **76.00 €***
~~Suggested retail price: 110.00 €*~~

Spare parts

Consumable spares:



Battery SR44 1,5 V

Art No. 938882
Suggested retail price: 7.00 €*