

Digital Micrometer Head, IP65

Item number: 350-281-30

Images



Description

This Micrometer Head has a 25 mm range and a 12 mm stem, and offers the following benefits:


- You can integrate it into machinery and measuring instruments.
- Its excellent water and dust resistance (IP65 protection level) lets you use it in machining situations that include splashing coolant fluid (except types with threaded stem).

Features

| | |
|--------------------------------------|--|
| Model: | MHN1-25MX (IP65) |
| Digital/Analog: | Digital |
| Inch-Metric: | Metric |
| Range: | 0 - 25 mm |
| Digital step: | 0,001 mm |
| Max. Permissible Error J MPE: | ±2 µm |
| Spindle end: | Flat |
| Spindle pitch: | 0,5 mm |
| Stem Ø: | 12 mm |
| Stem: | Plain |
| Delivered: | Including spanner, SR44 battery |
| Remarks: | IP65 |
| Display: | LCD, character Height 7.5 mm |
| Measuring face: | Carbide tipped |
| Measuring spindle: | With spindle lock, Ø 6,35 mm |
| Scale: | Thimble and sleeve satin chrome finish |
| Data output: | Yes |
| Power supply: | 1 battery SR-44 |
| Battery life: | Approx. 2,4 years |

| | |
|--|-------|
| ABS / INC (INC ZERO): | Yes |
| Auto Power OFF after 20 min. non use: | Yes |
| Low voltage alarm: | Yes |
| Function lock: | Yes |
| HOLD: | Yes |
| 2 x PRESET: | Yes |
| Mass: | 230 g |

Dimensions

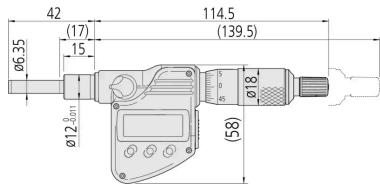

Accessories

Optional accessories:

Promotion!

Mitutoyo

MiCAT
the standard in world
metrology software
MeasurLink

USB-ITPAK Vers. 3.0

USB Dongle + Manual (Software available Online)

Art No. 06AGR543

Promo price: 268.00 €*

~~Suggested retail price: 340.00 €*~~





Digimatic Cable with Data Button IP Type

1 m, Micrometer Type
Art No. 05CZA662
Suggested retail price: 105.00 €*



Digimatic Cable with Data Button IP Type

2 m, Micrometer Type
Art No. 05CZA663
Suggested retail price: 107.00 €*

Promotion!



USB Input Tool Direct (Digimatic to USB)

2m Cable, Digimatic/Digimatic 2, with Data
Button IP Micrometer Type
Art No. 06AFM380B

Promo price: **111.00 €***

Suggested retail price: ~~141.00 €*~~

Promotion!



U-WAVE fit, IP67 Type

Wireless Transmitter for
Micrometer/Indicator
Art No. 264-622

Promo price: **129.00 €***

Suggested retail price: ~~185.00 €*~~

Promotion!



U-WAVE fit, Buzzer Type

Wireless Transmitter for
Micrometer/Indicator
Art No. 264-623

Promo price: **129.00 €***

Suggested retail price: ~~185.00 €*~~

Promotion!



U-WAVE fit Bluetooth, IP67 Type

Wireless Transmitter for
Micrometer/Indicator
Art No. 264-626

Promo price: **129.00 €***

Suggested retail price: ~~185.00 €*~~

Promotion!



U-WAVE fit Bluetooth, Buzzer Type

Wireless Transmitter for
Micrometer/Indicator
Art No. 264-627

Promo price: **129.00 €***

Suggested retail price: ~~185.00 €*~~

Promotion!



Connection Unit for IP Caliper, Micrometer

with Data Button for U-WAVE fit, U-WAVE fit
Bluetooth

Art No. 02AZF310

Promo price: **76.00 €***

~~Suggested retail price: 110.00 €*~~

Spare parts

Consumable spares:



Battery SR44 1,5 V

Art No. 938882

Suggested retail price: **7.00 €***