


## Digital Micrometer Head

Item number: 350-351-30

### Images

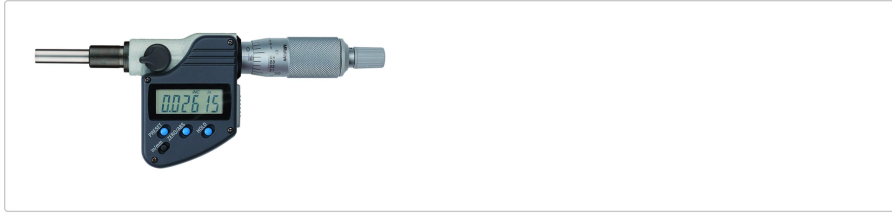

### Description

A Mitutoyo digital micrometer head with plain  $\lambda=10$ mm stem and flat spindle tip. Ratchet stop. Digimatic data output.

### Features

<b>Digital/Analog:</b>	Digital
<b>Inch-Metric:</b>	Inch/Metric
<b>Range:</b>	0 - 1 "
<b>Digital step:</b>	0.00005"/0.001 mm
<b>Max. Permissible Error J MPE:</b>	$\pm 0.0001$ "
<b>Spindle end:</b>	Flat
<b>Stem <math>\varnothing</math>:</b>	0.375"
<b>Stem:</b>	Plain
<b>Delivered:</b>	Including spanner, SR44 battery
<b>Display:</b>	LCD, character Height 7.5 mm
<b>Measuring face:</b>	Carbide tipped
<b>Measuring spindle:</b>	With spindle lock, $\varnothing 6,35$ mm
<b>Scale:</b>	Thimble and sleeve satin chrome finish
<b>Data output:</b>	Yes
<b>Power supply:</b>	1 battery SR-44
<b>Battery life:</b>	Approx. 2,4 years
<b>ABS / INC (INC ZERO):</b>	Yes
<b>Auto Power OFF after 20 min. non use:</b>	Yes
<b>Low voltage alarm:</b>	Yes
<b>Function lock:</b>	Yes
<b>HOLD:</b>	Yes
<b>2 x PRESET:</b>	Yes
<b>Mass:</b>	230 g

### Dimensions

