


Digital Micrometer Head

Item number: 350-352-30

Images

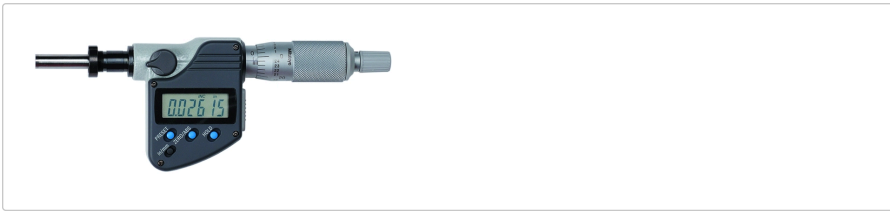

Description

This Micrometer Head has a 25 mm range and a 10 mm stem, and offers the following benefits:

- You can integrate it into machinery and measuring instruments.
- Measurement values are clearly displayed in 0.001mm increments.
- Stem diameter: 10 mm.

Features

Digital/Analog:	Digital
Inch-Metric:	Inch/Metric
Range:	0 - 1 "
Digital step:	0.00005"/0.001 mm
Max. Permissible Error J MPE:	±0.0001"
Spindle end:	Flat
Stem Ø:	0.375"
Stem:	w/ clamp nut
Fixture thickness for clamp nut:	11.5 mm
Delivered:	Including spanner, SR44 battery
Display:	LCD, character Height 7.5 mm
Measuring face:	Carbide tipped
Measuring spindle:	With spindle lock, ø 6,35 mm
Scale:	Thimble and sleeve satin chrome finish
Data output:	Yes
Power supply:	1 battery SR-44
Battery life:	Approx. 2,4 years
ABS / INC (INC ZERO):	Yes
Auto Power OFF after 20 min. non use:	Yes
Low voltage alarm:	Yes
Function lock:	Yes
HOLD:	Yes
2 x PRESET:	Yes
Mass:	230 g

