

2-Point Internal Micrometer

Holtest

Item number: 368-001

Images




Description

A non-digital 2-point Mitutoyo bore micrometer suitable for measuring the diameter of small holes. Hardened steel contact faces. Ratchet stop guarantees repeatable measurement. Steel setting rings (optional) are available for accurate setting prior to measurement.

Features

Digital/Analog:	Analog
Inch-Metric:	Metric
Range:	2 - 2.5 mm
Graduation:	0,001 mm
Max. Permissible Error J MPE:	±2 µm
Scale:	Thimble and sleeve satin chrome finish, Up to 12 mm : Ø 17 mm Over 12 mm : Ø 23 mm
Measuring spindle:	Spindle pitch 0,5 mm
Measuring face:	Tungsten carbide
Measuring method:	2-point
Delivered:	Including box, hex wrench, certificate of inspection, without setting ring
Mass:	88 g


Dimensions

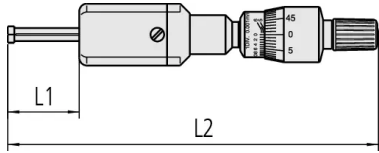

c: 2 mm

L1: 12 mm

L2: 103.5 - 104 mm

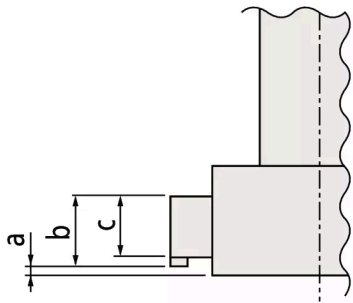

c: 2 mm

L1: 12 mm

L2: 103.5 - 104 mm

Accessories

Optional accessories:



Setting Ring 2,0mm

Steel

Art No. 177-239

Suggested retail price: 126.00 €*



Setting Ring 2,5mm

Steel

Art No. 177-208

Suggested retail price: 126.00 €*