

## 2-Point Internal Micrometer

### Holtest

Item number: 368-021

#### Images



#### Description


These are three-point and two-point internal micrometers that offer you the following benefits:

- Titanium-coated measuring pins give you excellent durability and impact resistance (3-point type).
- Three-point micrometer allows stable measurement through automatic centring.
- It is delivered without setting rings or extensions.

#### Features

<b>Digital/Analog:</b>	Analog
<b>Inch-Metric:</b>	Inch
<b>Range:</b>	0,08 - 0,1 "
<b>Graduation:</b>	≤ 0.5": 0.0001", >0.5": 0.0002"
<b>Scale:</b>	Thimble and sleeve satin chrome finish, Up to 0.5" : ø 17 mm Over 0.5" : ø 23 mm
<b>Measuring spindle:</b>	Spindle pitch 0,635 mm
<b>Measuring face:</b>	Tungsten carbide
<b>Measuring method:</b>	2-point
<b>Delivered:</b>	Including box, hex wrench, certificate of inspection, without setting ring
<b>Mass:</b>	88 g


#### Dimensions

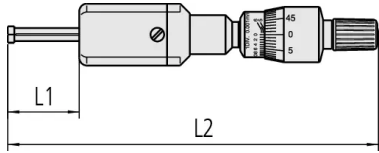

**c:** 2 mm

**L1:** 12 - 12 mm

**L2:** 93 mm

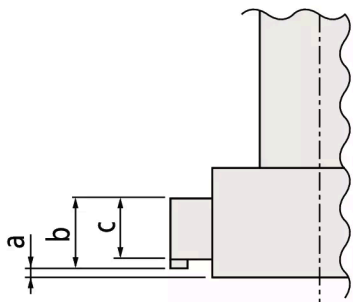

**c:** 2 mm

**L1:** 12 - 12 mm

**L2:** 93 mm

## Accessories

Optional accessories:



### Setting Ring 0,1"

Steel

Art No. 177-209

Suggested retail price: 120.00 €\*