

2-Point Internal Micrometer

Holtest

Item number: 368-024

Images



Description


These are three-point and two-point internal micrometers that offer you the following benefits:

- Titanium-coated measuring pins give you excellent durability and impact resistance (3-point type).
- Three-point micrometer allows stable measurement through automatic centring.
- It is delivered without setting rings or extensions.


Features

Digital/Analog:	Analog
Inch-Metric:	Inch
Range:	0,16 - 0,2 "
Graduation:	≤ 0.5": 0.0001", >0.5": 0.0002"
Scale:	Thimble and sleeve satin chrome finish, Up to 0.5" : ø 17 mm Over 0.5" : ø 23 mm
Measuring spindle:	Spindle pitch 0,635 mm
Measuring face:	Tungsten carbide
Measuring method:	2-point
Delivered:	Including box, hex wrench, certificate of inspection, without setting ring
Mass:	91 g

Dimensions

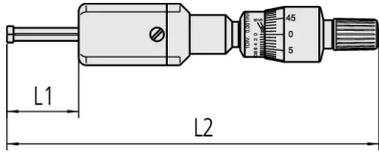

c: 2 mm
L1: 22 - 22 mm
L2: 93 mm

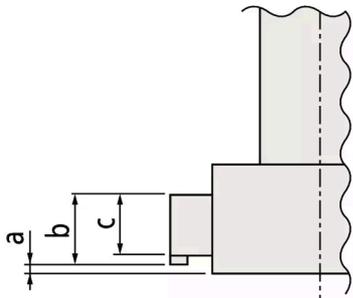

c: 2 mm
L1: 22 - 22 mm
L2: 93 mm

Accessories

Optional accessories:



Setting Ring 0,16"

Steel
 Art No. 177-206
 Suggested retail price: 120.00 €*



Setting Ring 0,16"

Ceramic
 Art No. 177-518
 Suggested retail price: 268.00 €*