

## 2-Point Internal Micrometer

### Holtest

Item number: 368-025

#### Images



#### Description


These are three-point and two-point internal micrometers that offer you the following benefits:

- Titanium-coated measuring pins give you excellent durability and impact resistance (3-point type).
- Three-point micrometer allows stable measurement through automatic centring.
- It is delivered without setting rings or extensions.


#### Features

<b>Inch-Metric:</b>	Inch
<b>Digital/Analog:</b>	Analog
<b>Range:</b>	0,2 - 0,24 "
<b>Graduation:</b>	≤ 0.5": 0.0001", >0.5": 0.0002"
<b>Scale:</b>	Thimble and sleeve satin chrome finish, Up to 0.5" : ø 17 mm Over 0.5" : ø 23 mm
<b>Measuring spindle:</b>	Spindle pitch 0,635 mm
<b>Measuring face:</b>	Tungsten carbide
<b>Measuring method:</b>	2-point
<b>Delivered:</b>	Including box, hex wrench, certificate of inspection, without setting ring
<b>Mass:</b>	91 g

#### Dimensions

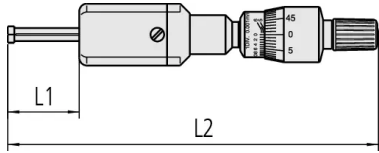

**c:** 2 mm  
**L1:** 22 - 22 mm  
**L2:** 93 mm

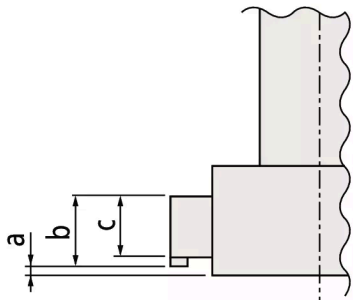

**c:** 2 mm  
**L1:** 22 - 22 mm  
**L2:** 93 mm

## Accessories

### Optional accessories:



### Setting Ring 0,24"

Steel  
 Art No. 177-207  
 Suggested retail price: 120.00 €\*



### Setting Ring 0,24"

Ceramic  
 Art No. 177-520  
 Suggested retail price: 268.00 €\*