

3-Point Internal Micrometer

Holtest

Item number: 368-167

Images



Description

A non-digital 3-point Mitutoyo bore micrometer with titanium-coated measuring pins. The 3-point design enables stable measurement through automatic centering. The maximum measuring depth can be increased by 150mm using an optional extension rod if required. Ratchet stop guarantees repeatable measurement. Steel setting rings (optional) are available for accurate setting prior to measurement.


Features

Digital/Analog:	Analog
Inch-Metric:	Metric
Range:	25 - 30 mm
Graduation:	0,005 mm
Max. Permissible Error J MPE:	±3 µm
Scale:	Thimble and sleeve satin chrome finish, Up to 12 mm : Ø 17 mm

Over 12 mm : Ø 23 mm

Measuring spindle:	Spindle pitch 0,5 mm
Measuring face:	Titanium coated hardened steel taper: tungsten carbide
Measuring method:	3-point
Delivered:	Including box, spanner, hex wrench, certificate of inspection, without setting ring
Mass:	280 g

Dimensions

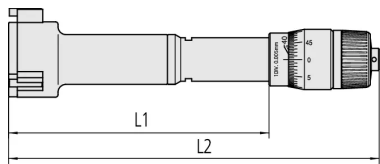


a: 0.3 mm

b: 8.3 mm

c: 5.2 mm

L1: 94 mm

L2: 137 - 142 mm

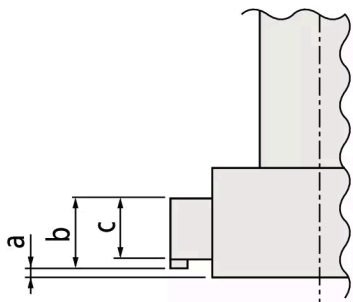

a: 0.3 mm

b: 8.3 mm

c: 5.2 mm

L1: 94 mm

L2: 137 - 142 mm

Accessories

Optional accessories:



Holtest, Borematic Extension 150mm

for 20-50mm Measuring Range

Art No. 952622

Suggested retail price: 128.00 €*



Setting Ring 25mm

Steel

Art No. 177-139

Suggested retail price: 150.00 €*



Setting Ring 25mm

Ceramic
Art No. 177-430
Suggested retail price: 323.00 €*



Setting Ring 30mm

Steel
Art No. 177-288
Suggested retail price: 174.00 €*



Setting Ring 30mm

Ceramic
Art No. 177-431
Suggested retail price: 403.00 €*
