

3-Point Internal Micrometer

Holtest

Item number: 368-169

Images



Description

A non-digital 3-point Mitutoyo bore micrometer with titanium-coated measuring pins. The 3-point design enables stable measurement through automatic centering. The maximum measuring depth can be increased by 150mm using an optional extension rod if required. Ratchet stop guarantees repeatable measurement. Steel setting rings (optional) are available for accurate setting prior to measurement.


Features

| | |
|--|--|
| Digital/Analog: | Analog |
| Inch-Metric: | Metric |
| Range: | 40 - 50 mm |
| Graduation: | 0,005 mm |
| Max. Permissible Error J MPE: | $\pm 3 \mu\text{m}$ |
| Scale: | Thimble and sleeve satin chrome finish, Up to 12 mm : $\varnothing 17 \text{ mm}$ Over 12 mm : $\varnothing 23 \text{ mm}$ |
| Measuring spindle: | Spindle pitch 0,5 mm |
| Measuring face: | Titanium coated hardened steel taper: tungsten carbide |
| Measuring method: | 3-point |
| Delivered: | Including box, spanner, hex wrench, certificate of inspection, without setting ring |

Mass:

330 g

Dimensions

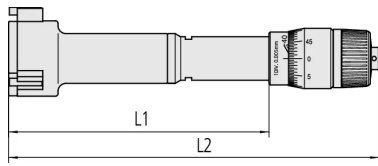


a: 0.3 mm

b: 13 mm

c: 10 mm

L1: 102 mm

L2: 145 - 155 mm

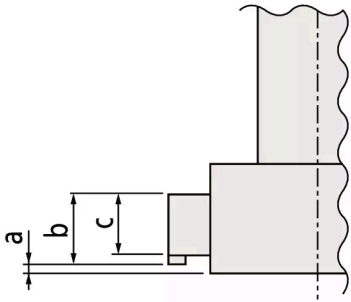

a: 0.3 mm

b: 13 mm

c: 10 mm

L1: 102 mm

L2: 145 - 155 mm

Accessories

Optional accessories:



Holtest, Borematic Extension 150mm

for 20-50mm Measuring Range
Art No. 952622
Suggested retail price: 128.00 €*



Setting Ring 40mm

Steel
Art No. 177-290
Suggested retail price: 203.00 €*



Setting Ring 40mm

Ceramic
Art No. 177-433
Suggested retail price: 440.00 €*

Setting Ring 50mm

Steel

Art No. 177-146

Suggested retail price: 215.00 €*

