

## 3-Point Internal Micrometer

### Holtest

Item number: 368-171

#### Images



#### Description

A non-digital 3-point Mitutoyo bore micrometer with titanium-coated measuring pins. The 3-point design enables stable measurement through automatic centering. The maximum measuring depth can be increased by 150mm using an optional extension rod if required. Ratchet stop guarantees repeatable measurement. Steel setting rings (optional) are available for accurate setting prior to measurement.


#### Features

<b>Digital/Analog:</b>	Analog
<b>Inch-Metric:</b>	Metric
<b>Range:</b>	62 - 75 mm
<b>Graduation:</b>	0,005 mm
<b>Max. Permissible Error J MPE:</b>	±4 μm
<b>Scale:</b>	Thimble and sleeve satin chrome finish, Up to 12 mm : Ø 17 mm Over 12 mm : Ø 23 mm
<b>Measuring spindle:</b>	Spindle pitch 0,5 mm
<b>Measuring face:</b>	Titanium coated hardened steel taper: tungsten carbide
<b>Measuring method:</b>	3-point
<b>Delivered:</b>	Including box, spanner, hex wrench, certificate of inspection, without setting ring

Mass:

450 g

## Dimensions

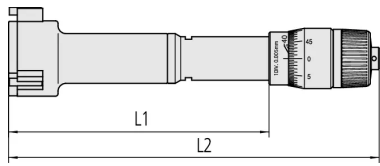


**a:** 0.3 mm

**b:** 17 mm

**c:** 14 mm

**L1:** 105 mm

**L2:** 150 - 163 mm

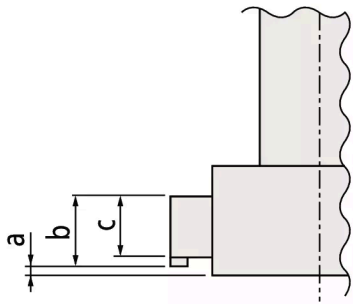

**a:** 0.3 mm

**b:** 17 mm

**c:** 14 mm

**L1:** 105 mm

**L2:** 150 - 163 mm

## Accessories

### Optional accessories:



### Holtest, Borematic Extension 150mm

for 50-300mm Measuring Range

Art No. 952623

Suggested retail price: 222.00 €\*



### Setting Ring 62mm

Steel

Art No. 177-314

Suggested retail price: 293.00 €\*



### Setting Ring 75mm

Steel

Art No. 177-316

Suggested retail price: 365.00 €\*

