

## 3-Point Internal Micrometer

### Holtest

Item number: 368-174

#### Images



#### Description

A non-digital 3-point Mitutoyo bore micrometer with titanium-coated measuring pins. The 3-point design enables stable measurement through automatic centering. The maximum measuring depth can be increased by 150mm using an optional extension rod if required. Ratchet stop guarantees repeatable measurement. Steel setting rings (optional) are available for accurate setting prior to measurement.


#### Features

<b>Digital/Analog:</b>	Analog
<b>Inch-Metric:</b>	Metric
<b>Range:</b>	100 - 125 mm
<b>Graduation:</b>	0,005 mm
<b>Max. Permissible Error J MPE:</b>	±5 µm
<b>Scale:</b>	Thimble and sleeve satin chrome finish, Up to 12 mm : Ø 17 mm Over 12 mm : Ø 23 mm
<b>Measuring spindle:</b>	Spindle pitch 0,5 mm
<b>Measuring face:</b>	Titanium coated hardened steel taper: tungsten carbide
<b>Measuring method:</b>	3-point
<b>Delivered:</b>	Including box, spanner, hex wrench, certificate of inspection, without setting ring

Mass:

1030 g

## Dimensions

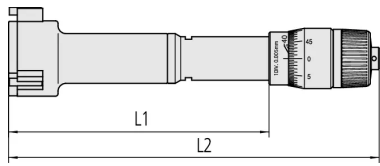


**a:** 12.4 mm

**b:** 21 mm

**c:** 13.8 mm

**L1:** 161 mm

**L2:** 227 - 252 mm

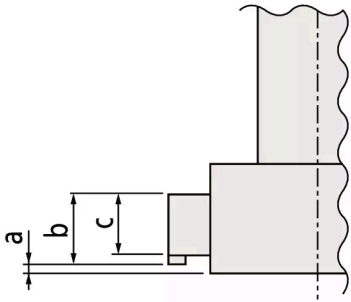

**a:** 12.4 mm

**b:** 21 mm

**c:** 13.8 mm

**L1:** 161 mm

**L2:** 227 - 252 mm

## Accessories

Optional accessories:



### Holtest, Borematic Extension 150mm

for 50-300mm Measuring Range

Art No. 952623

Suggested retail price: 222.00 €\*



### Setting Ring 100mm

Steel

Art No. 177-296

Suggested retail price: 521.00 €\*



### Setting Ring 125mm

Steel

Art No. 177-298

Suggested retail price: 989.00 €\*

