

3-Point Internal Micrometer

Holtest

Item number: 368-175

Images



Description

A non-digital 3-point Mitutoyo bore micrometer with titanium-coated measuring pins. The 3-point design enables stable measurement through automatic centering. The maximum measuring depth can be increased by 150mm using an optional extension rod if required. Ratchet stop guarantees repeatable measurement. Steel setting rings (optional) are available for accurate setting prior to measurement.


Features

Inch-Metric:	Metric
Digital/Analog:	Analog
Range:	125 - 150 mm
Graduation:	0,005 mm
Max. Permissible Error J MPE:	±5 µm
Scale:	Thimble and sleeve satin chrome finish, Up to 12 mm : Ø 17 mm Over 12 mm : Ø 23 mm
Measuring spindle:	Spindle pitch 0,5 mm
Measuring face:	Titanium coated hardened steel taper: tungsten carbide
Measuring method:	3-point
Delivered:	Including box, spanner, hex wrench, certificate of inspection, without setting ring

Mass:

1120 g

Dimensions

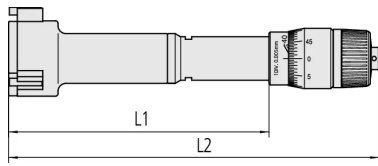


a: 12.4 mm

b: 21 mm

c: 13.8 mm

L1: 161 mm

L2: 227 - 252 mm

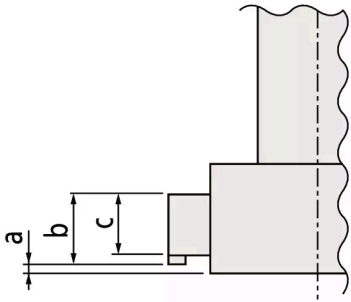

a: 12.4 mm

b: 21 mm

c: 13.8 mm

L1: 161 mm

L2: 227 - 252 mm

Accessories

Optional accessories:



Holtest, Borematic Extension 150mm

for 50-300mm Measuring Range
Art No. 952623
Suggested retail price: 216.00 €*



Setting Ring 125mm

Steel
Art No. 177-298
Suggested retail price: 989.00 €*



Setting Ring 150mm

Steel
Art No. 177-300
Suggested retail price: 1,033.00 €*

