

3-Point Internal Micrometer

Holtest

Item number: 368-177

Images



Description

These are three-point and two-point internal micrometers that offer you the following benefits:

- Titanium-coated measuring pins give you excellent durability and impact resistance (3-point type).
- Three-point micrometer allows stable measurement through automatic centring.
- It is delivered without setting rings or extensions.


Features

| | |
|--|---|
| Digital/Analog: | Analog |
| Inch-Metric: | Metric |
| Range: | 175 - 200 mm |
| Graduation: | 0,005 mm |
| Max. Permissible Error J MPE: | ±5 µm |
| Scale: | Thimble and sleeve satin chrome finish, Up to 12 mm : Ø 17 mm Over 12 mm : Ø 23 mm |
| Measuring spindle: | Spindle pitch 0,5 mm |
| Measuring face: | Titanium coated hardened steel taper: tungsten carbide |
| Measuring method: | 3-point |
| Delivered: | Including box, spanner, hex wrench, certificate of inspection, without setting ring |

Mass:

1320 g

Dimensions

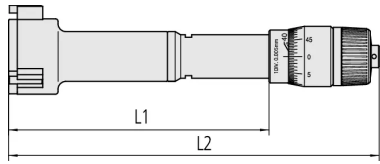


a: 12.4 mm

b: 21 mm

c: 13.8 mm

L1: 161 mm

L2: 227 - 252 mm

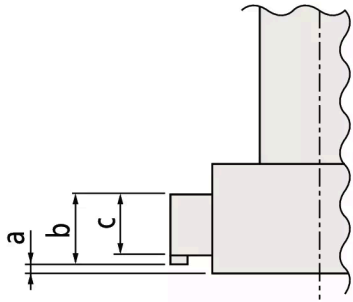

a: 12.4 mm

b: 21 mm

c: 13.8 mm

L1: 161 mm

L2: 227 - 252 mm

Accessories

Optional accessories:



Holtest, Borematic Extension 150mm

for 50-300mm Measuring Range
Art No. 952623
Suggested retail price: 222.00 €*



Setting Ring 175mm

Steel
Art No. 177-302
Suggested retail price: 1,235.00 €*



Setting Ring 200mm

Steel
Art No. 177-304
Suggested retail price: 1,944.00 €*

