

## 3-Point Internal Micrometer

### Holtest

Item number: 368-178

#### Images



#### Description

These are three-point and two-point internal micrometers that offer you the following benefits:

- Titanium-coated measuring pins give you excellent durability and impact resistance (3-point type).
- Three-point micrometer allows stable measurement through automatic centring.
- It is delivered without setting rings or extensions.


#### Features

|  |  |
|--|--|
| <b>Inch-Metric:</b>                      | Metric   |
| <b>Digital/Analog:</b>                   | Analog   |
| <b>Range:</b>                            | 200 - 225 mm   |
| <b>Graduation:</b>                       | 0,005 mm   |
| <b>Max. Permissible Error<br/>J MPE:</b> | $\pm 6 \mu\text{m}$  |
| <b>Scale:</b>                            | Thimble and sleeve satin chrome finish,<br>Up to 12 mm : $\varnothing 17 \text{ mm}$<br>Over 12 mm : $\varnothing 23 \text{ mm}$ |
| <b>Measuring spindle:</b>                | Spindle pitch 0,5 mm   |
| <b>Measuring face:</b>                   | Titanium coated hardened steel<br>taper: tungsten carbide  |
| <b>Measuring method:</b>                 | 3-point  |
| <b>Delivered:</b>                        | Including box, spanner, hex wrench,<br>certificate of inspection, without setting<br>ring  |

Mass:

1430 g

## Dimensions

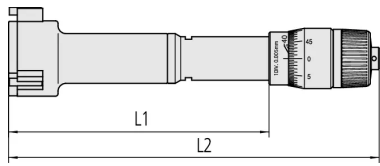


**a:** 12.4 mm

**b:** 21 mm

**c:** 13.8 mm

**L1:** 161 mm

**L2:** 227 - 252 mm

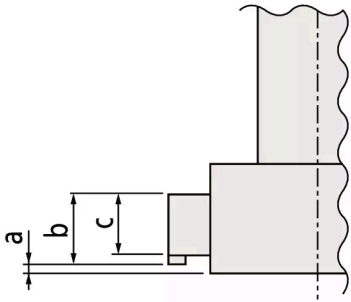

**a:** 12.4 mm

**b:** 21 mm

**c:** 13.8 mm

**L1:** 161 mm

**L2:** 227 - 252 mm

## Accessories

### Optional accessories:



### Holtest, Borematic Extension 150mm

for 50-300mm Measuring Range  
Art No. 952623  
Suggested retail price: 216.00 €\*



### Setting Ring 200mm

Steel  
Art No. 177-304  
Suggested retail price: 1,944.00 €\*



### Setting Ring 225mm

Steel  
Art No. 177-306  
Suggested retail price: 2,177.00 €\*

