

3-Point Internal Micrometer

Holtest

Item number: 368-179

Images



Description

These are three-point and two-point internal micrometers that offer you the following benefits:

- Titanium-coated measuring pins give you excellent durability and impact resistance (3-point type).
- Three-point micrometer allows stable measurement through automatic centring.
- It is delivered without setting rings or extensions.


Features

Inch-Metric:	Metric
Digital/Analog:	Analog
Range:	225 - 250 mm
Graduation:	0,005 mm
Max. Permissible Error J MPE:	$\pm 6 \mu\text{m}$
Scale:	Thimble and sleeve satin chrome finish, Up to 12 mm : $\varnothing 17 \text{ mm}$ Over 12 mm : $\varnothing 23 \text{ mm}$
Measuring spindle:	Spindle pitch 0,5 mm
Measuring face:	Titanium coated hardened steel taper: tungsten carbide
Measuring method:	3-point
Delivered:	Including box, spanner, hex wrench, certificate of inspection, without setting ring

Mass:

1550 g

Dimensions

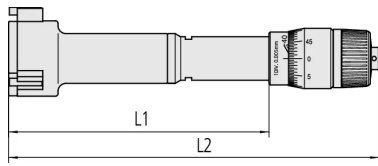


a: 12.4 mm

b: 21 mm

c: 13.8 mm

L1: 161 mm

L2: 227 - 252 mm

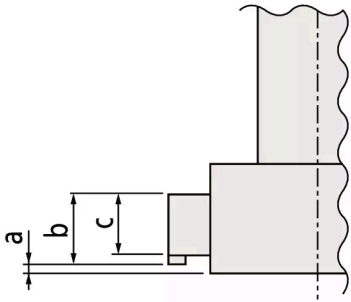

a: 12.4 mm

b: 21 mm

c: 13.8 mm

L1: 161 mm

L2: 227 - 252 mm

Accessories

Optional accessories:



Holtest, Borematic Extension 150mm

for 50-300mm Measuring Range
Art No. 952623
Suggested retail price: 216.00 €*



Setting Ring 225mm

Steel
Art No. 177-306
Suggested retail price: 2,177.00 €*



Setting Ring 250mm

Steel
Art No. 177-308
Suggested retail price: 2,364.00 €*

