

## 3-Point Internal Micrometer

### Holtest

Item number: 368-180

#### Images



#### Description

These are three-point and two-point internal micrometers that offer you the following benefits:

- Titanium-coated measuring pins give you excellent durability and impact resistance (3-point type).
- Three-point micrometer allows stable measurement through automatic centring.
- It is delivered without setting rings or extensions.


#### Features

<b>Inch-Metric:</b>	Metric
<b>Digital/Analog:</b>	Analog
<b>Range:</b>	250 - 275 mm
<b>Graduation:</b>	0,005 mm
<b>Max. Permissible Error J MPE:</b>	$\pm 6 \mu\text{m}$
<b>Scale:</b>	Thimble and sleeve satin chrome finish, Up to 12 mm : $\varnothing 17 \text{ mm}$ Over 12 mm : $\varnothing 23 \text{ mm}$
<b>Measuring spindle:</b>	Spindle pitch 0,5 mm
<b>Measuring face:</b>	Titanium coated hardened steel taper: tungsten carbide
<b>Measuring method:</b>	3-point
<b>Delivered:</b>	Including box, spanner, hex wrench, certificate of inspection, without setting ring

Mass:

1700 g

## Dimensions

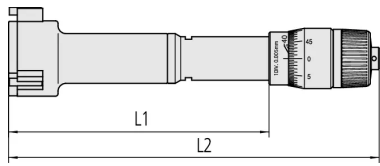


**a:** 12.4 mm

**b:** 21 mm

**c:** 13.8 mm

**L1:** 161 mm

**L2:** 227 - 252 mm

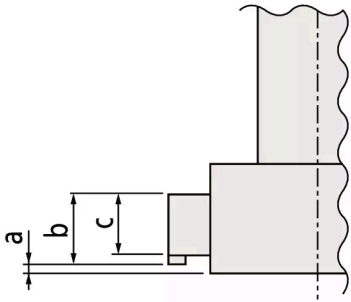

**a:** 12.4 mm

**b:** 21 mm

**c:** 13.8 mm

**L1:** 161 mm

**L2:** 227 - 252 mm

## Accessories

### Optional accessories:



### Holtest, Borematic Extension 150mm

for 50-300mm Measuring Range  
Art No. 952623  
Suggested retail price: 216.00 €\*



### Setting Ring 250mm

Steel  
Art No. 177-308  
Suggested retail price: 2,364.00 €\*



### Setting Ring 275mm

Steel  
Art No. 177-310  
Suggested retail price: 2,723.00 €\*

