


3-Point Internal Micrometer

Holtest

Item number: 368-262

Images

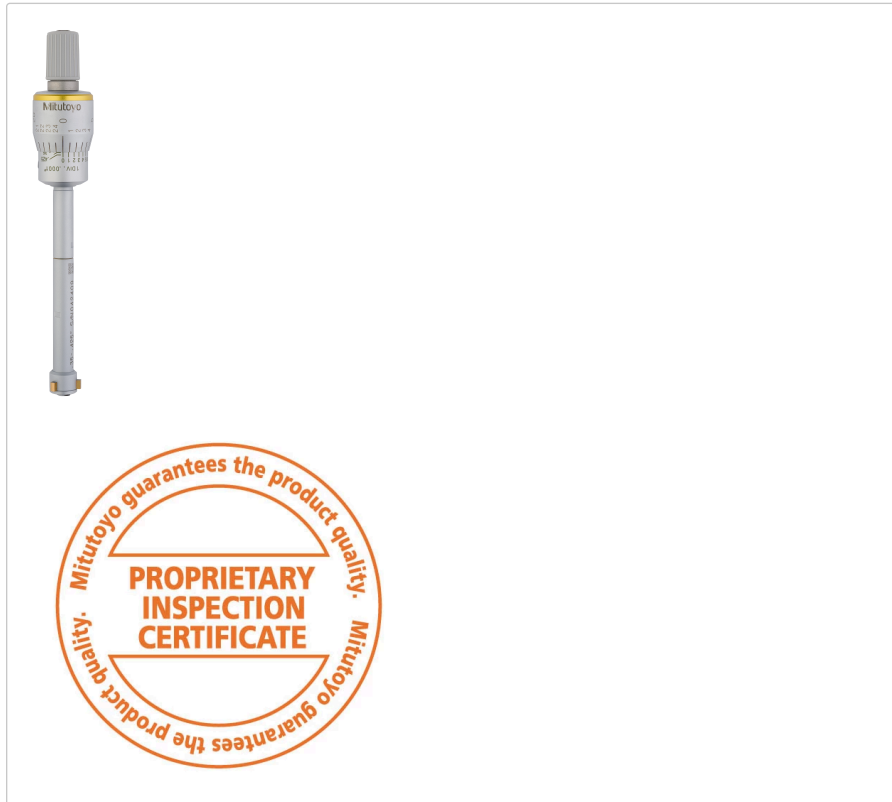


Description

- For setting 2-point bore gauges series 511.
- The Bore Gauge Checker allows easy setting of dial bore gauges with ranges of 18 mm through 400 mm using gauge blocks.

Features

Inch-Metric:	Inch
Digital/Analog:	Analog
Range:	0,35 - 0,425 "
Graduation:	≤ 0.5": 0.0001", >0.5": 0.0002"
Scale:	Thimble and sleeve satin chrome finish, Up to 0.5" : ø 17 mm Over 0.5" : ø 23 mm
Measuring spindle:	Spindle pitch 0,635 mm
Measuring face:	Titanium coated tungsten carbide Taper: tungsten carbide
Measuring method:	3-point
Delivered:	Including box, spanner, hex wrench, certificate of inspection, without setting ring
Mass:	60 g

Dimensions

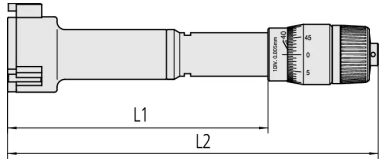


a: 2 mm

c: 2.5 mm

L1: 59 - 59 mm

L2: 102 - 104 mm

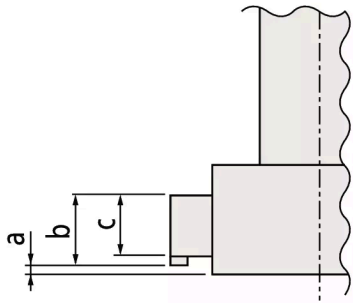

a: 2 mm

 
c: 2.5 mm

L1: 59 - 59 mm

L2: 102 - 104 mm

Accessories

Optional accessories:



Holtest, Borematic Extension 100mm

for 6-12mm Measuring Range

Art No. 952322

Suggested retail price: 128.00 €*



Setting Ring 0,35"

Steel

Art No. 177-179

Suggested retail price: 126.00 €*



Setting Ring 0,35"

Ceramic

Art No. 177-523

Suggested retail price: 268.00 €*



Setting Ring 0,425"

Steel

Art No. 177-283

Suggested retail price: 121.00 €*



Setting Ring 0,425"

Ceramic

Art No. 177-524

Suggested retail price: 268.00 €*
