

## 3-Point Internal Micrometer

### Holtest

Item number: 368-265

#### Images



#### Description


These are three-point and two-point internal micrometers that offer you the following benefits:

- Titanium-coated measuring pins give you excellent durability and impact resistance (3-point type).
- Three-point micrometer allows stable measurement through automatic centring.
- It is delivered without setting rings or extensions.

#### Features

<b>Digital/Analog:</b>	Analog
<b>Inch-Metric:</b>	Inch
<b>Range:</b>	0,65 - 0,8 "
<b>Graduation:</b>	≤ 0.5": 0.0001", >0.5": 0.0002"
<b>Scale:</b>	Thimble and sleeve satin chrome finish, Up to 0.5" : ø 17 mm Over 0.5" : ø 23 mm
<b>Measuring spindle:</b>	Spindle pitch 0,635 mm
<b>Measuring face:</b>	Titanium coated hardened steel Taper: tungsten carbide
<b>Measuring method:</b>	3-point
<b>Delivered:</b>	Including box, spanner, hex wrench, certificate of inspection, without setting ring
<b>Mass:</b>	160 g

#### Dimensions

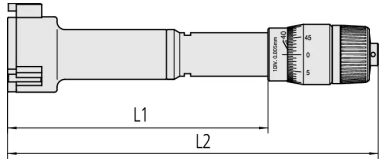


**a:** 0.3 mm

**b:** 5.6 mm

**c:** 3.5 mm

**L1:** 82 - 82 mm

**L2:** 126 - 130 mm

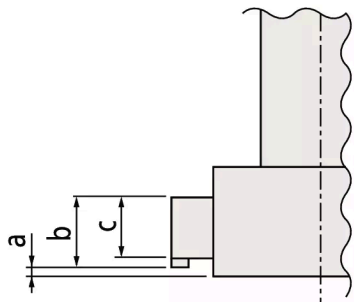

**a:** 0.3 mm

**b:** 5.6 mm

**c:** 3.5 mm

**L1:** 82 - 82 mm

**L2:** 126 - 130 mm

## Accessories

### Optional accessories:



### Holtest, Borematic Extension 150mm

for 12-20mm Measuring Range

Art No. 952621

Suggested retail price: 118.00 €\*



### Setting Ring 0,65"

Steel

Art No. 177-182

Suggested retail price: 120.00 €\*



### Setting Ring 0,65"

Ceramic

Art No. 177-527

Suggested retail price: 271.00 €\*



## Setting Ring 0,8"

Ceramic

Art No. 177-529

Suggested retail price: 315.00 €\*



## Setting Ring 0,8"

Steel

Art No. 177-287

Suggested retail price: 139.00 €\*