

3-Point Internal Micrometer

Holtest

Item number: 368-267

Images



Description


These are three-point and two-point internal micrometers that offer you the following benefits:

- Titanium-coated measuring pins give you excellent durability and impact resistance (3-point type).
- Three-point micrometer allows stable measurement through automatic centring.
- It is delivered without setting rings or extensions.

Features

Digital/Analog:	Analog
Inch-Metric:	Inch
Range:	1 - 1,2 "
Graduation:	≤ 0.5": 0.0001", >0.5": 0.0002"
Scale:	Thimble and sleeve satin chrome finish, Up to 0.5" : ø 17 mm Over 0.5" : ø 23 mm
Measuring spindle:	Spindle pitch 0,635 mm
Measuring face:	Titanium coated hardened steel Taper: tungsten carbide
Measuring method:	3-point
Delivered:	Including box, spanner, hex wrench, certificate of inspection, without setting ring
Mass:	280 g

Dimensions

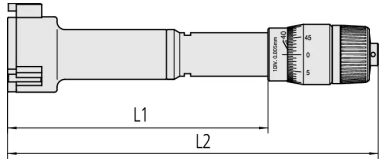


a: 0.3 mm

b: 8.3 mm

c: 5.2 mm

L1: 94 - 94 mm

L2: 137 - 142 mm

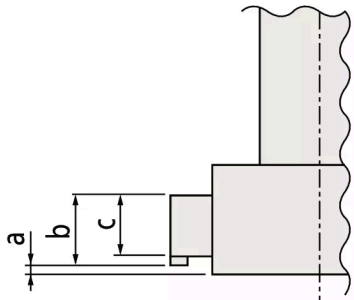

a: 0.3 mm

b: 8.3 mm

c: 5.2 mm

L1: 94 - 94 mm

L2: 137 - 142 mm

Accessories

Optional accessories:



Holtest, Borematic Extension 150mm

for 20-50mm Measuring Range

Art No. 952622

Suggested retail price: 128.00 €*



Setting Ring 1"

Steel

Art No. 177-184

Suggested retail price: 150.00 €*



Setting Ring 1,0"

Ceramic

Art No. 177-530

Suggested retail price: 323.00 €*



Setting Ring 1,2"

Ceramic

Art No. 177-531

Suggested retail price: 403.00 €*



Setting Ring 1,2"

Steel

Art No. 177-289

Suggested retail price: 174.00 €*
