

3-Point Internal Micrometer

Holtest

Item number: 368-270

Images



Description


These are three-point and two-point internal micrometers that offer you the following benefits:

- Titanium-coated measuring pins give you excellent durability and impact resistance (3-point type).
- Three-point micrometer allows stable measurement through automatic centring.
- It is delivered without setting rings or extensions.

Features

| | |
|---------------------------|---|
| Inch-Metric: | Inch |
| Digital/Analog: | Analog |
| Range: | 2,5 - 3 " |
| Graduation: | ≤ 0.5": 0.0001", >0.5": 0.0002" |
| Scale: | Thimble and sleeve satin chrome finish, Up to 0.5" : ø 17 mm Over 0.5" : ø 23 mm |
| Measuring spindle: | Spindle pitch 0,635 mm |
| Measuring face: | Titanium coated hardened steel Taper: tungsten carbide |
| Measuring method: | 3-point |
| Delivered: | Including box, spanner, hex wrench, certificate of inspection, without setting ring |
| Mass: | 440 g |

Dimensions

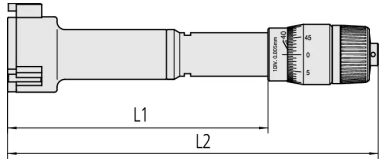


a: 0.3 mm

b: 17 mm

c: 14 mm

L1: 105 - 105 mm

L2: 150 - 163 mm

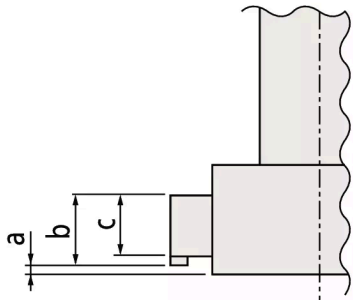

a: 0.3 mm

b: 17 mm

c: 14 mm

L1: 105 - 105 mm

L2: 150 - 163 mm

Accessories

Optional accessories:



Holtest, Borematic Extension 150mm

for 50-300mm Measuring Range

Art No. 952623

Suggested retail price: 216.00 €*



Setting Ring 2"

Steel

Art No. 177-187

Suggested retail price: 215.00 €*



Setting Ring 2,5"

Steel

Art No. 177-315

Suggested retail price: 344.00 €*

