

3-Point Internal Micrometer

Holtest

Item number: 368-273

Images



Description


These are three-point and two-point internal micrometers that offer you the following benefits:

- Titanium-coated measuring pins give you excellent durability and impact resistance (3-point type).
- Three-point micrometer allows stable measurement through automatic centring.
- It is delivered without setting rings or extensions.

Features

Inch-Metric:	Inch
Digital/Analog:	Analog
Range:	3,5 - 4 "
Graduation:	≤ 0.5": 0.0001", >0.5": 0.0002"
Scale:	Thimble and sleeve satin chrome finish, Up to 0.5" : ø 17 mm Over 0.5" : ø 23 mm
Measuring spindle:	Spindle pitch 0,635 mm
Measuring face:	Titanium coated hardened steel Taper: tungsten carbide
Measuring method:	3-point
Delivered:	Including box, spanner, hex wrench, certificate of inspection, without setting ring
Mass:	580 g

Dimensions

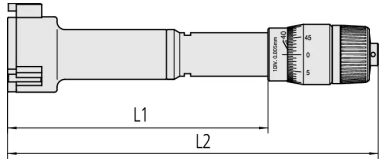


a: 0.3 mm

b: 17 mm

c: 14 mm

L1: 105 - 105 mm

L2: 150 - 163 mm

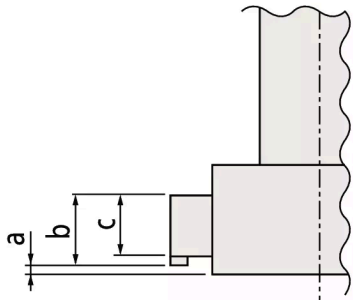

a: 0.3 mm

b: 17 mm

c: 14 mm

L1: 105 - 105 mm

L2: 150 - 163 mm

Accessories

Optional accessories:



Holtest, Borematic Extension 150mm

for 50-300mm Measuring Range

Art No. 952623

Suggested retail price: 216.00 €*



Setting Ring 3,5"

Steel

Art No. 177-319

Suggested retail price: 477.00 €*



Setting Ring 4"

Steel

Art No. 177-297

Suggested retail price: 521.00 €*

