


## 3-Point Internal Micrometer

### Holtest

Item number: 368-276

#### Images

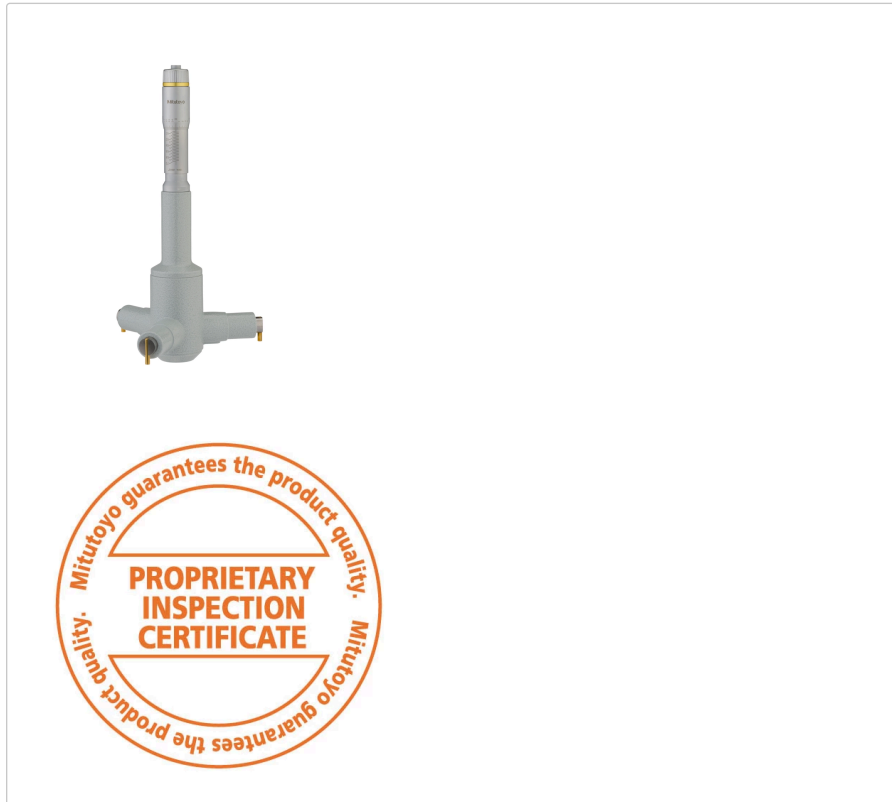

#### Description


These are three-point and two-point internal micrometers that offer you the following benefits:

- Titanium-coated measuring pins give you excellent durability and impact resistance (3-point type).
- Three-point micrometer allows stable measurement through automatic centring.
- It is delivered without setting rings or extensions.

#### Features

<b>Inch-Metric:</b>	Inch
<b>Digital/Analog:</b>	Analog
<b>Range:</b>	6 - 7 "
<b>Graduation:</b>	≤ 0.5": 0.0001", >0.5": 0.0002"
<b>Scale:</b>	Thimble and sleeve satin chrome finish, Up to 0.5" : ø 17 mm Over 0.5" : ø 23 mm
<b>Measuring spindle:</b>	Spindle pitch 0,635 mm
<b>Measuring face:</b>	Titanium coated hardened steel Taper: tungsten carbide
<b>Measuring method:</b>	3-point
<b>Delivered:</b>	Including box, spanner, hex wrench, certificate of inspection, without setting ring
<b>Mass:</b>	1210 g

#### Dimensions

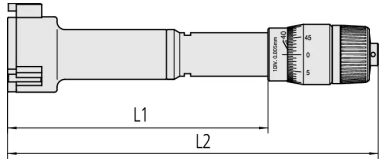


**a:** 12.4 mm

**b:** 21 mm

**c:** 13.8 mm

**L1:** 161 - 161 mm

**L2:** 227 - 252 mm

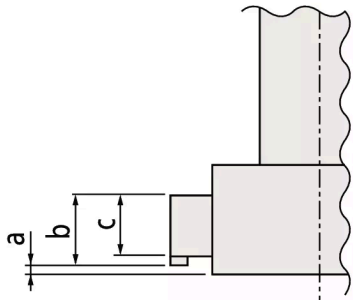

**a:** 12.4 mm

**b:** 21 mm

**c:** 13.8 mm

**L1:** 161 - 161 mm

**L2:** 227 - 252 mm

## Accessories

### Optional accessories:



### Holtest, Borematic Extension 150mm

for 50-300mm Measuring Range

Art No. 952623

Suggested retail price: 216.00 €\*



### Setting Ring 6"

Steel

Art No. 177-301

Suggested retail price: 1,061.00 €\*



### Setting Ring 7"

Steel

Art No. 177-303

Suggested retail price: 1,516.00 €\*

