


3-Point Internal Micrometer

Holtest

Item number: 368-280

Images

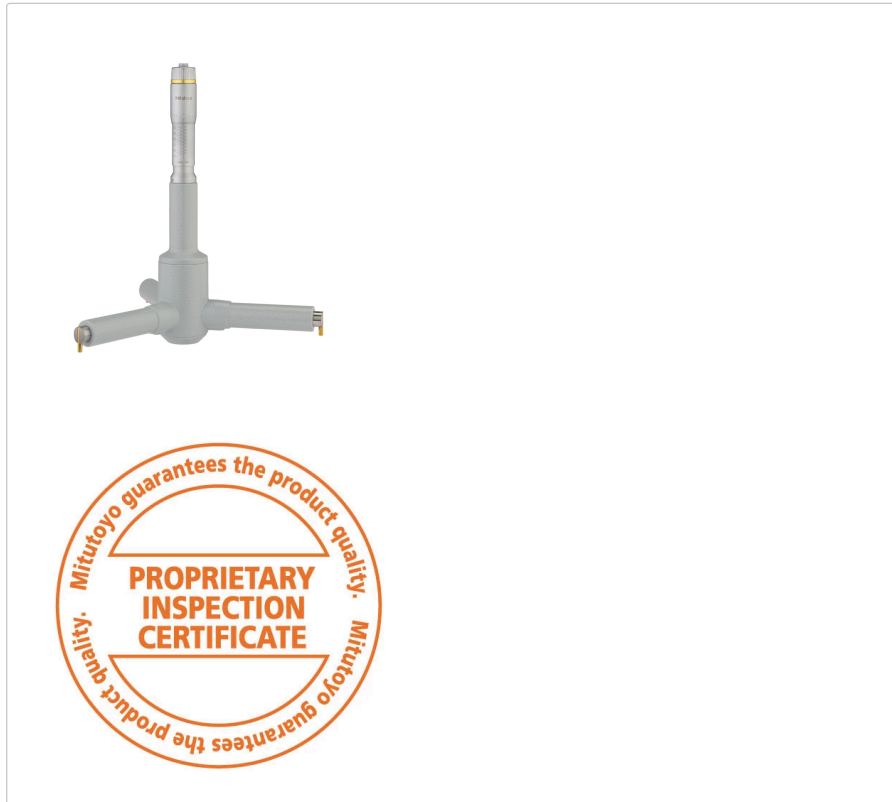

Description


These are three-point and two-point internal micrometers that offer you the following benefits:

- Titanium-coated measuring pins give you excellent durability and impact resistance (3-point type).
- Three-point micrometer allows stable measurement through automatic centring.
- It is delivered without setting rings or extensions.

Features

Digital/Analog:	Analog
Inch-Metric:	Inch
Range:	10 - 11 "
Graduation:	≤ 0.5 " : 0.0001", >0.5 " : 0.0002"
Scale:	Thimble and sleeve satin chrome finish, Up to 0.5" : \varnothing 17 mm Over 0.5" : \varnothing 23 mm
Measuring spindle:	Spindle pitch 0,635 mm
Measuring face:	Titanium coated hardened steel Taper: tungsten carbide
Measuring method:	3-point
Delivered:	Including box, spanner, hex wrench, certificate of inspection, without setting ring
Mass:	1700 g

Dimensions

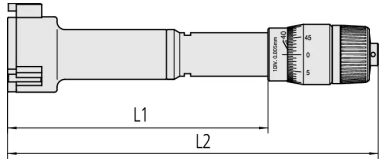


a: 12.4 mm

b: 21 mm

c: 13.8 mm

L1: 161 - 161 mm

L2: 227 - 252 mm

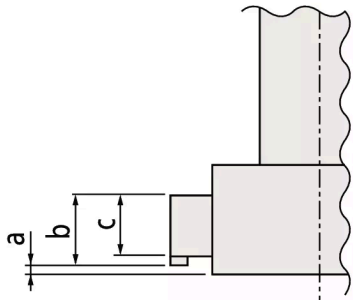

a: 12.4 mm

b: 21 mm

c: 13.8 mm

L1: 161 - 161 mm

L2: 227 - 252 mm

Accessories

Optional accessories:



Holtest, Borematic Extension 150mm

for 50-300mm Measuring Range

Art No. 952623

Suggested retail price: 222.00 €*



Setting Ring 10"

Steel

Art No. 177-309

Suggested retail price: 2,364.00 €*



Setting Ring 11"

Steel

Art No. 177-311

Suggested retail price: 2,723.00 €*

