

3-Point Internal Micrometer Holtest

Item number: 368-764

Images



Description


A non-digital Mitutoyo bore gauge. Hardened steel contact faces. A ratchet stop guarantees repeatable measurement.

Features

| | |
|--|--|
| Digital/Analog: | Analog |
| Inch-Metric: | Metric |
| Range: | 12 - 16 mm |
| Graduation: | 0,005 mm |
| Max. Permissible Error J MPE: | $\pm 3 \mu\text{m}$ |
| Scale: | Thimble and sleeve satin chrome finish, Up to 12 mm : $\text{\O} 17 \text{ mm}$ Over 12 mm : $\text{\O} 23 \text{ mm}$ |

| | |
|---------------------------|---|
| Measuring spindle: | Spindle pitch 0,5 mm |
| Measuring face: | Hardened steel taper: hardened steel |
| Measuring method: | 3-point |
| Delivered: | Including box, spanner, hex wrench, certificate of inspection, without setting ring |
| Mass: | 150 g |

Dimensions

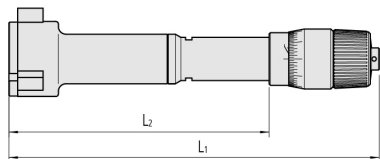


a: 2.6 mm

b: 3.5 mm

L1: 126 - 130 mm

L2: 82 mm

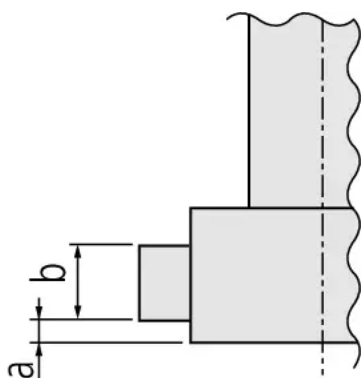

a: 2.6 mm

b: 3.5 mm

L1: 126 - 130 mm

L2: 82 mm

Accessories

Optional accessories:



Holtest, Borematic Extension 150mm

for 12-20mm Measuring Range

Art No. 952621

Suggested retail price: 118.00 €*



Setting Ring 12mm

Steel

Art No. 177-284

Suggested retail price: 126.00 €*



Setting Ring 12mm

Ceramic
Art No. 177-425
Suggested retail price: 271.00 €*



Setting Ring 16mm

Steel
Art No. 177-177
Suggested retail price: 126.00 €*



Setting Ring 16mm

Ceramic
Art No. 177-427
Suggested retail price: 271.00 €*
