

3-Point Internal Micrometer

Holtest

Item number: 368-765

Images




Description

A non-digital Mitutoyo bore gauge. Hardened steel contact faces. A ratchet stop guarantees repeatable measurement.

Features

Inch-Metric:	Metric
Digital/Analog:	Analog
Range:	16 - 20 mm
Graduation:	0,005 mm
Max. Permissible Error J MPE:	$\pm 3 \mu\text{m}$
Scale:	Thimble and sleeve satin chrome finish, Up to 12 mm : $\varnothing 17 \text{ mm}$ Over 12 mm : $\varnothing 23 \text{ mm}$
Measuring spindle:	Spindle pitch 0,5 mm
Measuring face:	hardened steel Taper: hardened steel
Measuring method:	3-point
Delivered:	Including box, spanner, hex wrench, certificate of inspection, without setting ring
Mass:	150 g

Dimensions

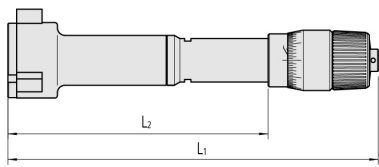


a: 2.6 mm

b: 3.5 mm

L1: 126 - 130 mm

L2: 82 mm

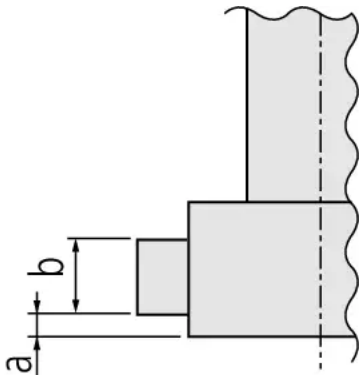

a: 2.6 mm

b: 3.5 mm

L1: 126 - 130 mm

L2: 82 mm

Accessories

Optional accessories:



Holtest, Borematic Extension 150mm

for 12-20mm Measuring Range
Art No. 952621
Suggested retail price: 120.00 €*



Setting Ring 16mm

Steel
Art No. 177-177
Suggested retail price: 126.00 €*



Setting Ring 16mm

Ceramic
Art No. 177-427
Suggested retail price: 271.00 €*



Setting Ring 20mm

Steel

Art No. 177-286

Suggested retail price: 139.00 €*



Setting Ring 20mm

Ceramic

Art No. 177-429

Suggested retail price: 315.00 €*
