

3-Point Internal Micrometer

Holtest

Item number: 368-766

Images



Description


A non-digital Mitutoyo bore gauge. Hardened steel contact faces. A ratchet stop guarantees repeatable measurement.

Features

Inch-Metric:	Metric
Digital/Analog:	Analog
Range:	20 - 25 mm
Graduation:	0,005 mm
Max. Permissible Error J MPE:	±3 µm
Scale:	Thimble and sleeve satin chrome finish, Up to 12 mm : Ø 17 mm Over 12 mm : Ø 23 mm

Measuring spindle:	Spindle pitch 0,5 mm
Measuring face:	hardened steel Taper: hardened steel
Measuring method:	3-point
Delivered:	Including box, spanner, hex wrench, certificate of inspection, without setting ring
Mass:	260 g

Dimensions

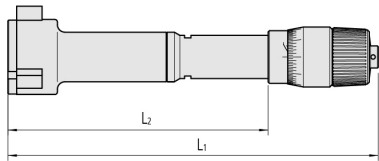


a: 3.4 mm

b: 5.2 mm

L1: 137 - 142 mm

L2: 94 mm

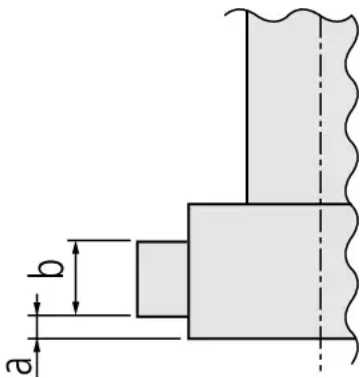

a: 3.4 mm

b: 5.2 mm

L1: 137 - 142 mm

L2: 94 mm

Accessories

Optional accessories:



Holtest, Borematic Extension 150mm

for 20-50mm Measuring Range

Art No. 952622

Suggested retail price: 136.00 €*



Setting Ring 20mm

Steel

Art No. 177-286

Suggested retail price: 139.00 €*



Setting Ring 20mm

Ceramic

Art No. 177-429

Suggested retail price: 315.00 €*



Setting Ring 25mm

Steel

Art No. 177-139

Suggested retail price: 150.00 €*



Setting Ring 25mm

Ceramic

Art No. 177-430

Suggested retail price: 323.00 €*