

3-Point Internal Micrometer Holtest

Item number: 368-767

Images



Description

A non-digital Mitutoyo bore gauge. Hardened steel contact faces. A ratchet stop guarantees repeatable measurement.

Features

Inch-Metric:	Metric
Digital/Analog:	Analog
Range:	25 - 30 mm
Graduation:	0,005 mm
Max. Permissible Error J MPE:	$\pm 3 \mu\text{m}$

Scale: Thimble and sleeve satin chrome finish,
Up to 12 mm : Ø 17 mm
Over 12 mm : Ø 23 mm

Measuring spindle: Spindle pitch 0,5 mm


Measuring face: hardened steel
Taper: hardened steel

Measuring method: 3-point

Delivered: Including box, spanner, hex wrench,
certificate of inspection, without setting
ring

Mass: 280 g

Dimensions

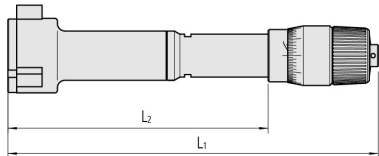


a: 3.4 mm

b: 5.2 mm

L1: 137 - 142 mm

L2: 94 mm

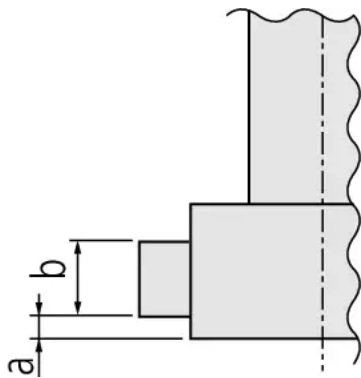

a: 3.4 mm

b: 5.2 mm

L1: 137 - 142 mm

L2: 94 mm

Accessories

Optional accessories:



Holtest, Borematic Extension 150mm

for 20-50mm Measuring Range

Art No. 952622

Suggested retail price: 136.00 €*



Setting Ring 25mm

Steel

Art No. 177-139

Suggested retail price: 150.00 €*



Setting Ring 25mm

Ceramic
Art No. 177-430
Suggested retail price: 323.00 €*



Setting Ring 30mm

Steel
Art No. 177-288
Suggested retail price: 174.00 €*



Setting Ring 30mm

Ceramic
Art No. 177-431
Suggested retail price: 403.00 €*
