

## 3-Point Internal Micrometer

### Holtest

Item number: 368-771

#### Images



#### Description

A non-digital Mitutoyo bore gauge. Hardened steel contact faces. A ratchet stop guarantees repeatable measurement.


#### Features

<b>Digital/Analog:</b>	Analog
<b>Inch-Metric:</b>	Metric
<b>Range:</b>	62 - 75 mm
<b>Graduation:</b>	0,005 mm
<b>Max. Permissible Error J MPE:</b>	±4 µm
<b>Scale:</b>	Thimble and sleeve satin chrome finish, Up to 12 mm : Ø 17 mm Over 12 mm : Ø 23 mm
<b>Measuring spindle:</b>	Spindle pitch 0,5 mm
<b>Measuring face:</b>	hardened steel Taper: hardened steel
<b>Measuring method:</b>	3-point
<b>Delivered:</b>	Including box, spanner, hex wrench, certificate of inspection, without setting ring

Mass:

450 g

## Dimensions

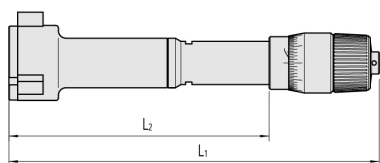


**a:** 3.4 mm

**b:** 14 mm

**L1:** 150 - 163 mm

**L2:** 105 mm

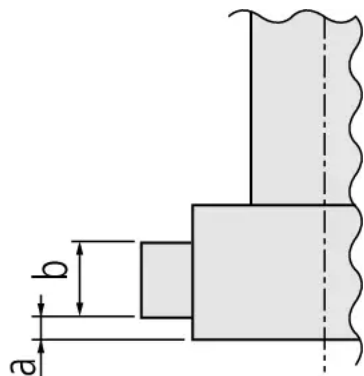

**a:** 3.4 mm

**b:** 14 mm

**L1:** 150 - 163 mm

**L2:** 105 mm

## Accessories

Optional accessories:




### Holtest, Borematic Extension 150mm

for 50-300mm Measuring Range

Art No. 952623

Suggested retail price: 222.00 €\*

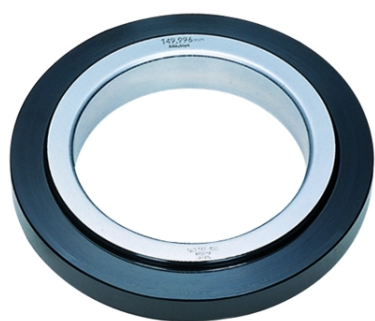

### Setting Ring 62mm

Steel

Art No. 177-314

Suggested retail price: 293.00 €\*



### Setting Ring 75mm

Steel

Art No. 177-316

Suggested retail price: 365.00 €\*

