

3-Point Internal Micrometer

Holtest

Item number: 368-775

Images



Description

A non-digital Mitutoyo bore gauge. Hardened steel contact faces. A ratchet stop guarantees repeatable measurement.


Features

Digital/Analog:	Analog
Inch-Metric:	Metric
Range:	125 - 150 mm
Graduation:	0,005 mm
Max. Permissible Error J MPE:	±5 µm
Scale:	Thimble and sleeve satin chrome finish, Up to 12 mm : Ø 17 mm


Over 12 mm : Ø 23 mm

Measuring spindle:	Spindle pitch 0,5 mm
Measuring face:	hardened steel Taper: hardened steel
Measuring method:	3-point
Delivered:	Including box, spanner, hex wrench, certificate of inspection, without setting ring
Mass:	1110 g

Dimensions

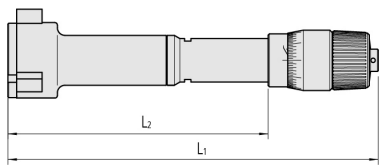

a: 19.6 mm
b: 13.8 mm
L1: 227 - 252 mm
L2: 161 mm

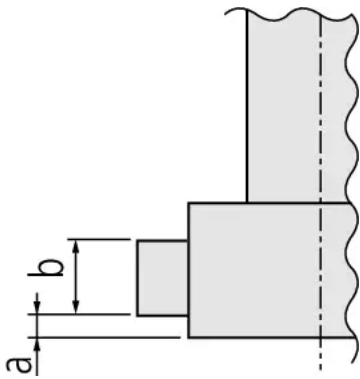

a: 19.6 mm
b: 13.8 mm
L1: 227 - 252 mm
L2: 161 mm

Accessories

Optional accessories:



Holtest, Borematic Extension 150mm

for 50-300mm Measuring Range
Art No. 952623
Suggested retail price: 222.00 €*



Setting Ring 125mm

Steel
Art No. 177-298
Suggested retail price: 989.00 €*



Setting Ring 150mm

Steel

Art No. 177-300

Suggested retail price: 1,033.00 €*
