


3-Point Internal Micrometer Holtest

Item number: 368-776

Images

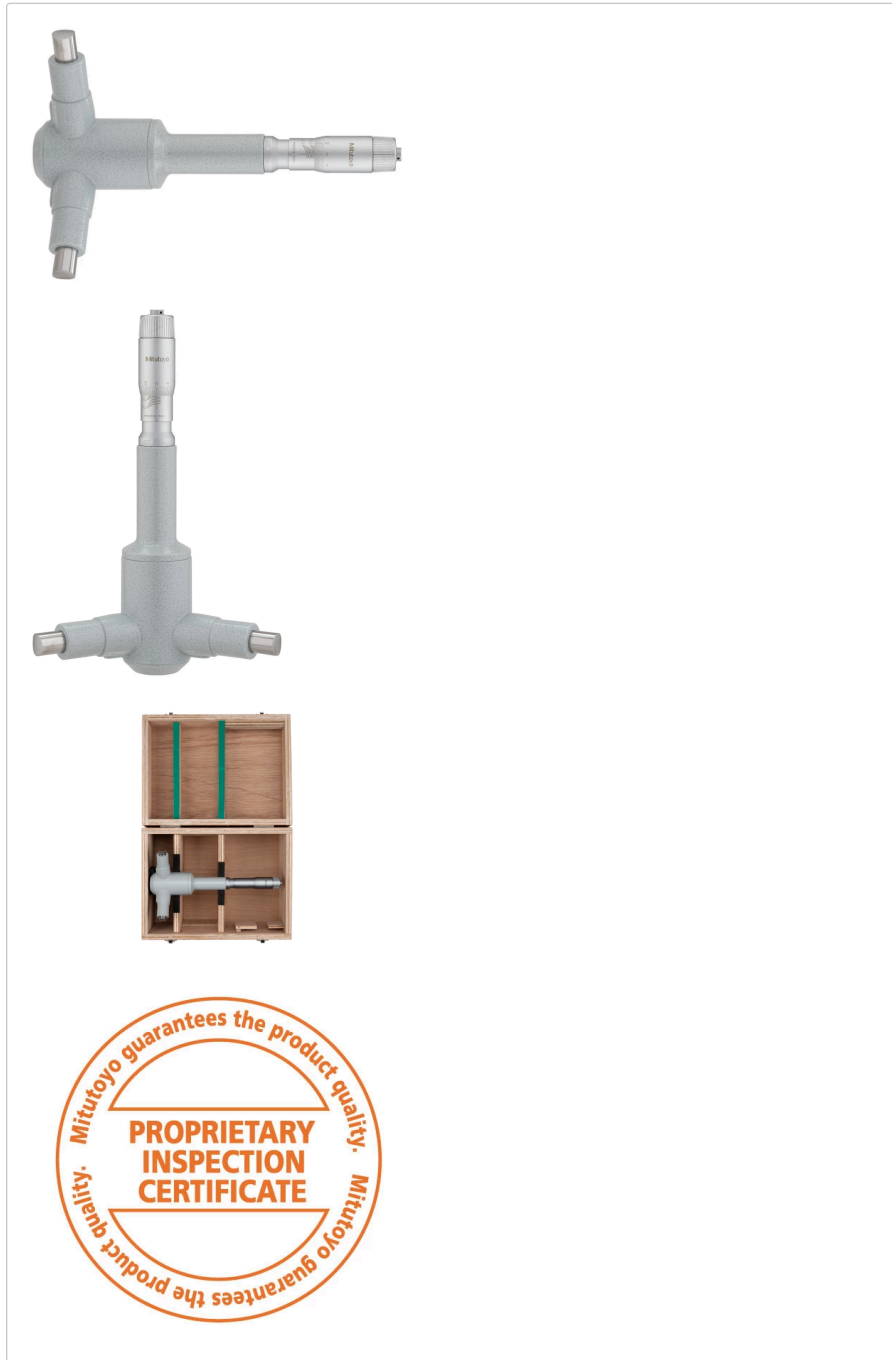

Description

A non-digital Mitutoyo bore gauge. Hardened steel contact faces. A ratchet stop guarantees repeatable measurement.

Features

Inch-Metric:	Metric
Digital/Analog:	Analog
Range:	150 - 175 mm
Graduation:	0,005 mm
Max. Permissible Error J MPE:	$\pm 5 \mu\text{m}$

Scale: Thimble and sleeve satin chrome finish,
Up to 12 mm : Ø 17 mm
Over 12 mm : Ø 23 mm

Measuring spindle: Spindle pitch 0,5 mm


Measuring face: hardened steel
Taper: hardened steel

Measuring method: 3-point

Delivered: Including box, spanner, hex wrench,
certificate of inspection, without setting
ring

Mass: 1200 g

Dimensions

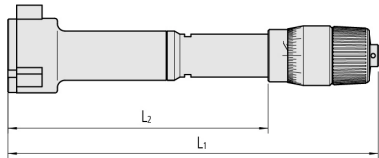


a: 19.6 mm

b: 13.8 mm

L1: 227 - 252 mm

L2: 161 mm

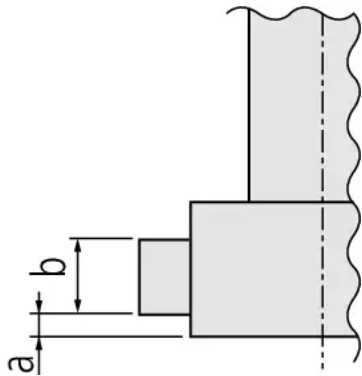

a: 19.6 mm

b: 13.8 mm

L1: 227 - 252 mm

L2: 161 mm

Accessories

Optional accessories:




Holtest, Borematic Extension 150mm

for 50-300mm Measuring Range

Art No. 952623

Suggested retail price: 216.00 €*

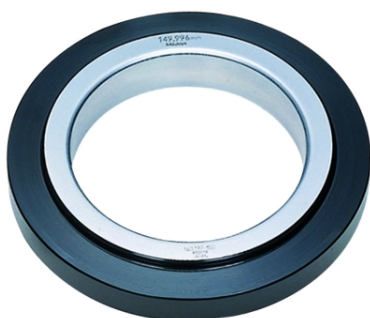

Setting Ring 150mm

Steel

Art No. 177-300

Suggested retail price: 1,033.00 €*



Setting Ring 175mm

Steel

Art No. 177-302

Suggested retail price: 1,235.00 €*
