

## 3-Point Internal Micrometer Holtest

Item number: 368-777

### Images



### Description

A non-digital Mitutoyo bore gauge. Hardened steel contact faces. A ratchet stop guarantees repeatable measurement.

### Features

<b>Digital/Analog:</b>	Analog
<b>Inch-Metric:</b>	Metric
<b>Range:</b>	175 - 200 mm
<b>Graduation:</b>	0,005 mm

**Max. Permissible Error J MPE:** ±5 µm

**Scale:** Thimble and sleeve satin chrome finish,  
Up to 12 mm : Ø 17 mm  
Over 12 mm : Ø 23 mm

**Measuring spindle:** Spindle pitch 0,5 mm


**Measuring face:** hardened steel  
Taper: hardened steel

**Measuring method:** 3-point

**Delivered:** Including box, spanner, hex wrench,  
certificate of inspection, without setting  
ring

**Mass:** 1300 g

## Dimensions

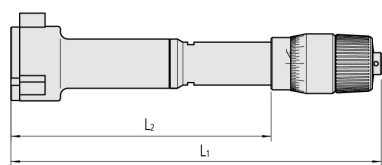


**a:** 19.6 mm

**b:** 13.8 mm

**L1:** 227 - 252 mm

**L2:** 161 mm

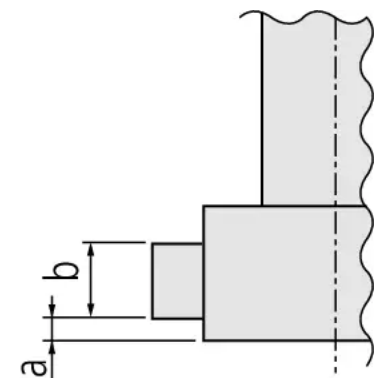

**a:** 19.6 mm

**b:** 13.8 mm

**L1:** 227 - 252 mm

**L2:** 161 mm

## Accessories

Optional accessories:



### Holtest, Borematic Extension 150mm

for 50-300mm Measuring Range

Art No. 952623

Suggested retail price: 222.00 €\*



## Setting Ring 175mm

Steel

Art No. 177-302

Suggested retail price: 1,235.00 €\*  
\*including 19% VAT



## Setting Ring 200mm

Steel

Art No. 177-304

Suggested retail price: 1,944.00 €\*  
\*including 19% VAT