

3-Point Internal Micrometer

Holtest

Item number: 368-778

Images



Description


A non-digital Mitutoyo bore gauge. Hardened steel contact faces. A ratchet stop guarantees repeatable measurement.

Features


Inch-Metric:	Metric
Digital/Analog:	Analog
Range:	200 - 225 mm
Graduation:	0,005 mm
Max. Permissible Error J MPE:	$\pm 6 \mu\text{m}$
Scale:	Thimble and sleeve satin chrome finish, Up to 12 mm : $\text{\O} 17 \text{ mm}$ Over 12 mm : $\text{\O} 23 \text{ mm}$
Measuring spindle:	Spindle pitch 0,5 mm

Measuring face:	hardened steel Taper: hardened steel
Measuring method:	3-point
Delivered:	Including box, spanner, hex wrench, certificate of inspection, without setting ring
Mass:	1420 g

Dimensions

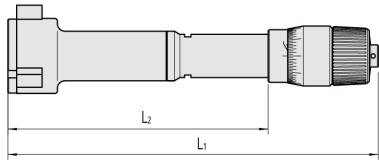

a: 19.6 mm
b: 13.8 mm
L1: 227 - 252 mm
L2: 161 mm

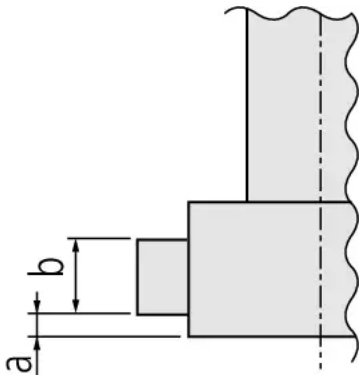

a: 19.6 mm
b: 13.8 mm
L1: 227 - 252 mm
L2: 161 mm

Accessories

Optional accessories:



Holtest, Borematic Extension 150mm

for 50-300mm Measuring Range
 Art No. 952623
 Suggested retail price: 216.00 €*



Setting Ring 200mm

Steel
 Art No. 177-304
 Suggested retail price: 1,944.00 €*



Setting Ring 225mm

Steel

Art No. 177-306

Suggested retail price: 2,177.00 €*
