

## 3-Point Internal Micrometer

### Holtest

Item number: 368-779

#### Images



#### Description


A non-digital Mitutoyo bore gauge. Hardened steel contact faces. A ratchet stop guarantees repeatable measurement.

#### Features


<b>Inch-Metric:</b>	Metric
<b>Digital/Analog:</b>	Analog
<b>Range:</b>	225 - 250 mm
<b>Graduation:</b>	0,005 mm
<b>Max. Permissible Error J MPE:</b>	$\pm 6 \mu\text{m}$
<b>Scale:</b>	Thimble and sleeve satin chrome finish, Up to 12 mm : $\text{\O} 17 \text{ mm}$ Over 12 mm : $\text{\O} 23 \text{ mm}$
<b>Measuring spindle:</b>	Spindle pitch 0,5 mm

<b>Measuring face:</b>	hardened steel Taper: hardened steel
<b>Measuring method:</b>	3-point
<b>Delivered:</b>	Including box, spanner, hex wrench, certificate of inspection, without setting ring
<b>Mass:</b>	1540 g

## Dimensions

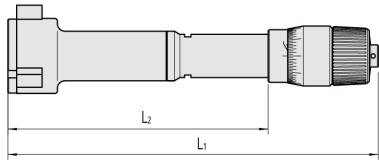

**a:** 19.6 mm  
**b:** 13.8 mm  
**L1:** 227 - 252 mm  
**L2:** 161 mm

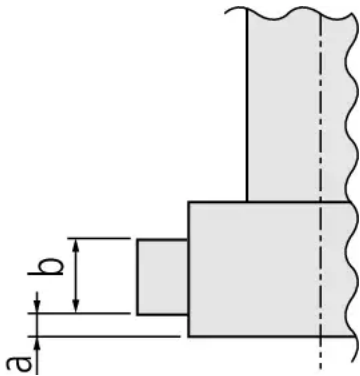

**a:** 19.6 mm  
**b:** 13.8 mm  
**L1:** 227 - 252 mm  
**L2:** 161 mm

## Accessories

### Optional accessories:



### Holtest, Borematic Extension 150mm

for 50-300mm Measuring Range  
 Art No. 952623  
 Suggested retail price: 216.00 €\*



### Setting Ring 225mm

Steel  
 Art No. 177-306  
 Suggested retail price: 2,177.00 €\*



## Setting Ring 250mm

Steel

Art No. 177-308

Suggested retail price: 2,364.00 €\*  

---