


3-Point Internal Micrometer Holtest

Item number: 368-780

Images

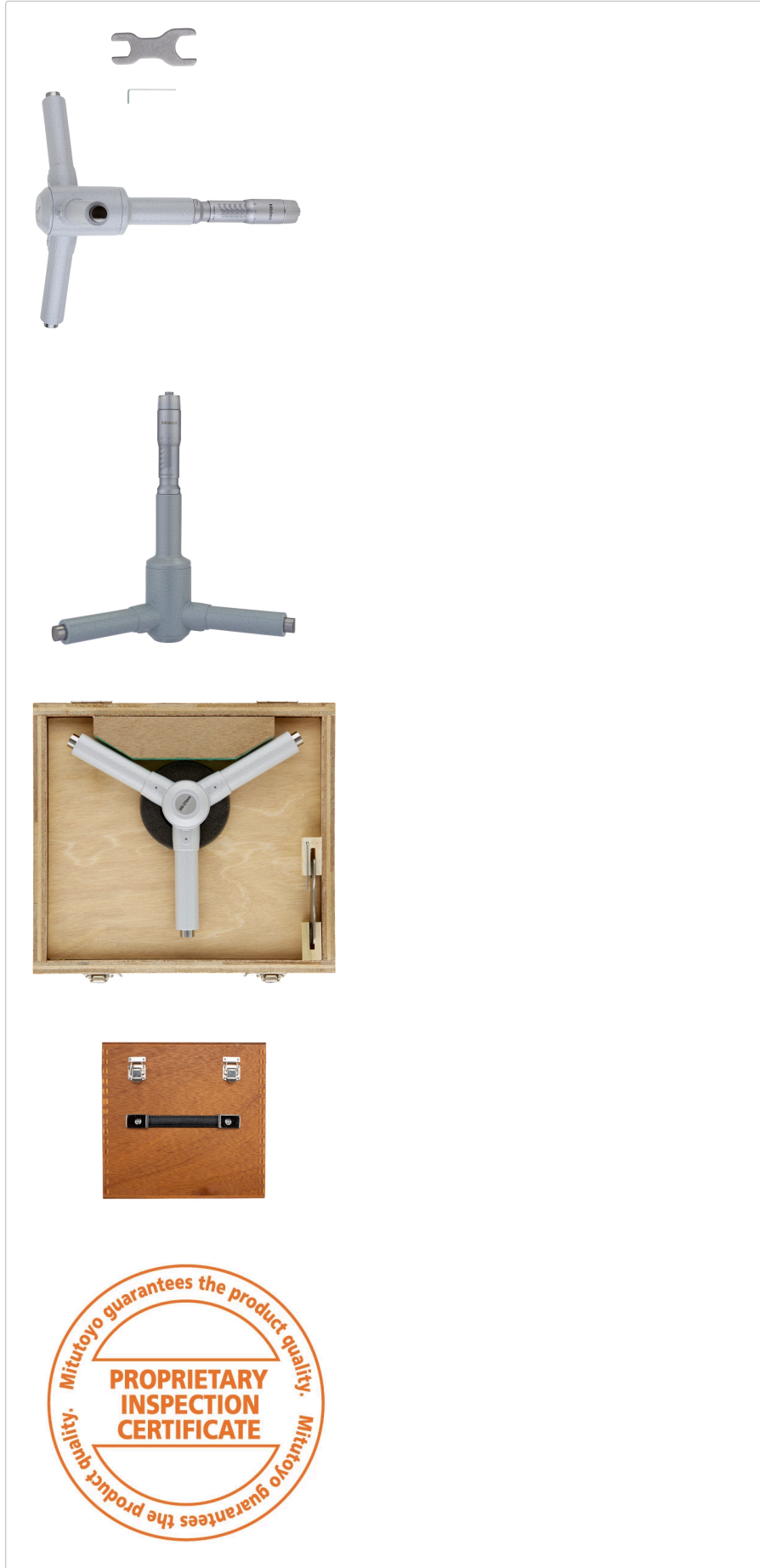


Description

A non-digital Mitutoyo bore gauge. Hardened steel contact faces. A ratchet stop guarantees repeatable measurement.

Features

Inch-Metric:	Metric
Digital/Analog:	Analog
Range:	250 - 275 mm
Graduation:	0,005 mm
Max. Permissible Error J MPE:	±6 µm
Scale:	Thimble and sleeve satin chrome finish, Up to 12 mm : Ø 17 mm Over 12 mm : Ø 23 mm
Measuring spindle:	Spindle pitch 0,5 mm
Measuring face:	hardened steel Taper: hardened steel
Measuring method:	3-point
Delivered:	Including box, spanner, hex wrench, certificate of inspection, without setting ring
Mass:	1690 g

Dimensions

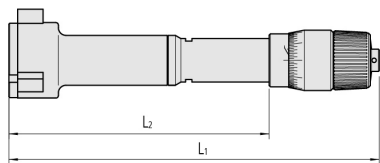


a: 19.6 mm

b: 13.8 mm

L1: 227 - 252 mm

L2: 161 mm

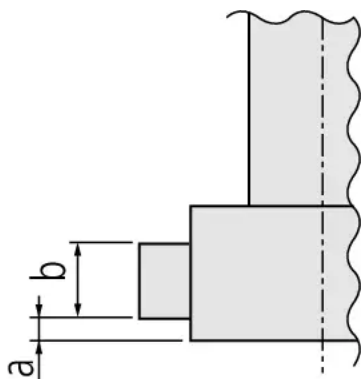

a: 19.6 mm

b: 13.8 mm

L1: 227 - 252 mm

L2: 161 mm


Accessories

Optional accessories:




Holtest, Borematic Extension 150mm

for 50-300mm Measuring Range
Art No. 952623
Suggested retail price: 216.00 €*

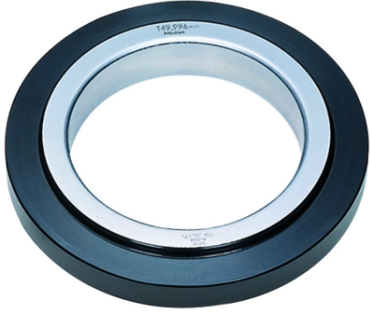

Setting Ring 250mm

Steel
Art No. 177-308
Suggested retail price: 2,364.00 €*

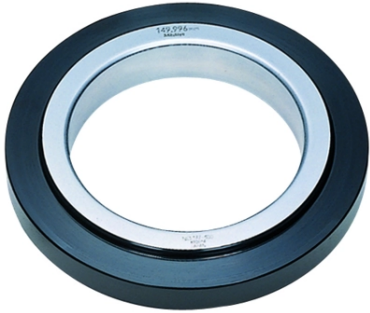

Setting Ring 275mm

Steel
Art No. 177-310
Suggested retail price: 2,723.00 €*
