

# 3-Point Internal Micrometer

## Holtest

Item number: 368-864

### Images




### Description

A non-digital Mitutoyo bore gauge. Hardened steel contact faces. A ratchet stop guarantees repeatable measurement.

### Features

<b>Inch-Metric:</b>	Inch
<b>Digital/Analog:</b>	Analog
<b>Range:</b>	0,5 - 0,65 "
<b>Graduation:</b>	≤ 0.5": 0.0001", >0.5": 0.0002"
<b>Scale:</b>	Thimble and sleeve satin chrome finish, Up to 12 mm : Ø 17 mm Over 12 mm : Ø 23 mm
<b>Measuring spindle:</b>	Spindle pitch 0,635 mm
<b>Measuring face:</b>	hardened steel Taper: hardened steel
<b>Measuring method:</b>	3-point
<b>Delivered:</b>	Including box, spanner, hex wrench, certificate of inspection, without setting ring
<b>Mass:</b>	150 g

### Dimensions

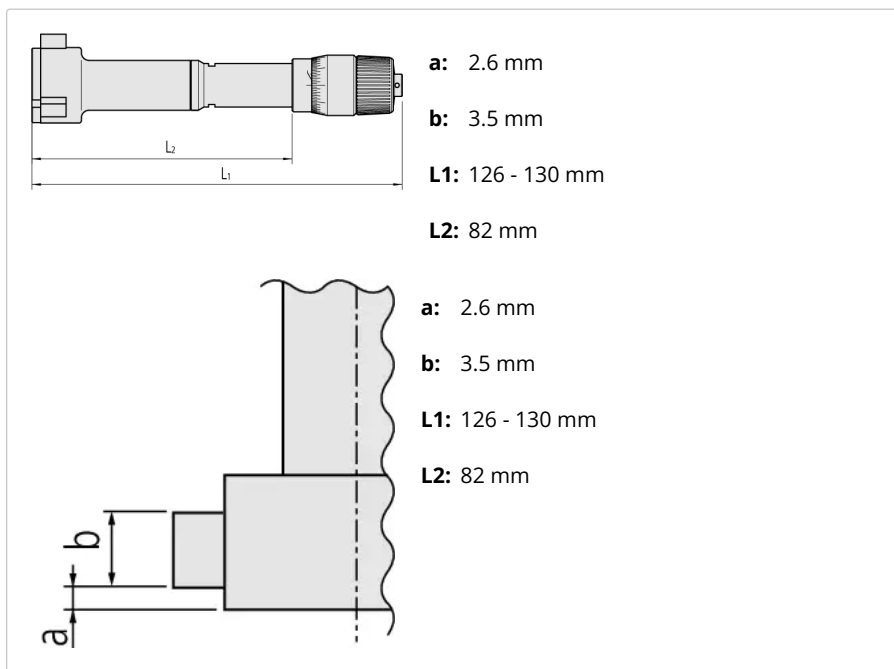

### Accessories

Optional accessories:



### Holtest, Borematic Extension 150mm

for 12-20mm Measuring Range  
Art No. 952621  
Suggested retail price: 120.00 €\*  

---



### Setting Ring 0,5"

Steel  
Art No. 177-180  
Suggested retail price: 120.00 €\*  

---



### Setting Ring 0,5"

Ceramic  
Art No. 177-525  
Suggested retail price: 271.00 €\*  

---



### Setting Ring 0,65"

Steel  
Art No. 177-182  
Suggested retail price: 120.00 €\*  

---



### Setting Ring 0,65"

Ceramic  
Art No. 177-527  
Suggested retail price: 271.00 €\*  

---

