

# 3-Point Internal Micrometer

## Holtest

Item number: 368-865

### Images




### Description

A non-digital Mitutoyo bore gauge. Hardened steel contact faces. A ratchet stop guarantees repeatable measurement.

### Features

<b>Inch-Metric:</b>	Inch
<b>Digital/Analog:</b>	Analog
<b>Range:</b>	0,65 - 0,8 "
<b>Graduation:</b>	≤ 0.5": 0.0001", >0.5": 0.0002"
<b>Scale:</b>	Thimble and sleeve satin chrome finish, Up to 12 mm : Ø 17 mm Over 12 mm : Ø 23 mm
<b>Measuring spindle:</b>	Spindle pitch 0,635 mm
<b>Measuring face:</b>	hardened steel Taper: hardened steel
<b>Measuring method:</b>	3-point
<b>Delivered:</b>	Including box, spanner, hex wrench, certificate of inspection, without setting ring
<b>Mass:</b>	150 g

### Dimensions

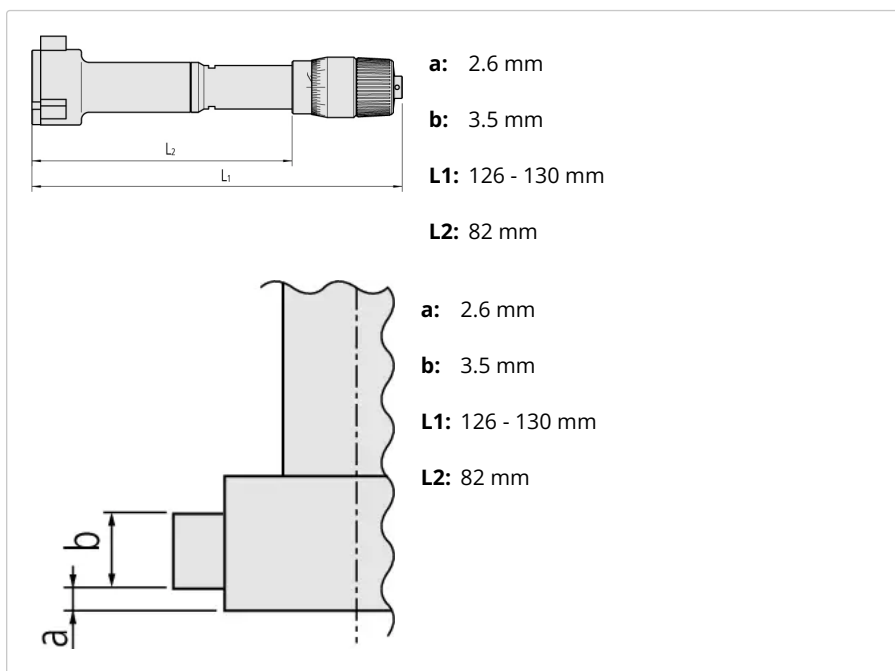

### Accessories

Optional accessories:



### Holtest, Borematic Extension 150mm

for 12-20mm Measuring Range

Art No. 952621

Suggested retail price: 120.00 €\*



### Setting Ring 0,65"

Steel

Art No. 177-182

Suggested retail price: 120.00 €\*



### Setting Ring 0,65"

Ceramic

Art No. 177-527

Suggested retail price: 271.00 €\*



### Setting Ring 0,8"

Ceramic

Art No. 177-529

Suggested retail price: 315.00 €\*



### Setting Ring 0,8"

Steel

Art No. 177-287

Suggested retail price: 139.00 €\*

