

3-Point Internal Micrometer

Holtest

Item number: 368-868

Images




Description

A non-digital Mitutoyo bore gauge. Hardened steel contact faces. A ratchet stop guarantees repeatable measurement.

Features

Inch-Metric:	Inch
Digital/Analog:	Analog
Range:	1,2 - 1,6 "
Graduation:	≤ 0.5": 0.0001", >0.5": 0.0002"
Scale:	Thimble and sleeve satin chrome finish, Up to 12 mm : Ø 17 mm Over 12 mm : Ø 23 mm
Measuring spindle:	Spindle pitch 0,635 mm
Measuring face:	hardened steel Taper: hardened steel
Measuring method:	3-point
Delivered:	Including box, spanner, hex wrench, certificate of inspection, without setting ring
Mass:	290 g

Dimensions

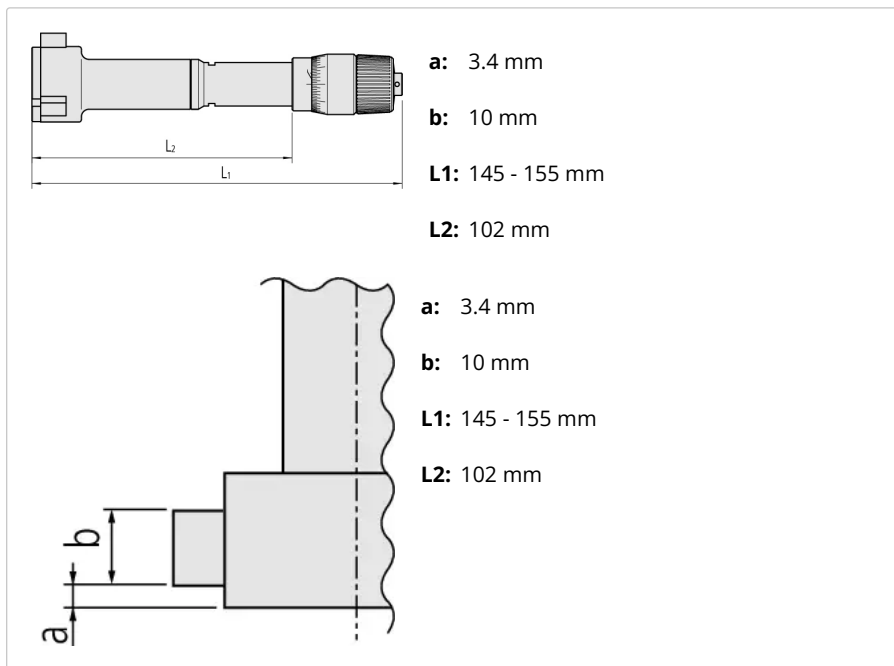

Accessories

Optional accessories:



Holtest, Borematic Extension 150mm

for 20-50mm Measuring Range
Art No. 952622
Suggested retail price: 136.00 €*



Setting Ring 1,2"

Steel
Art No. 177-289
Suggested retail price: 174.00 €*



Setting Ring 1,2"

Ceramic
Art No. 177-531
Suggested retail price: 403.00 €*



Setting Ring 1,6"

Ceramic
Art No. 177-533
Suggested retail price: 440.00 €*



Setting Ring 1,6"

Steel
Art No. 177-291
Suggested retail price: 203.00 €*

